

# Housing - HC-B 16-TFQ-H-O1STM40G - 1460157

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B16 sleeve housing, for double locking latch, height: 76 mm, with 1 x M40 thread, straight cable outlet



## Key commercial data

Packing unit	10 pc
GTIN	 4 046356 696029
Weight per Piece (excluding packing)	22.22 g
Custom tariff number	85389099
Country of origin	Germany

## Technical data

### Dimensions

Height	76 mm
Width	43 mm
Length	94 mm

### Ambient conditions

Degree of protection of housing (IP)	IP65
Ambient temperature (operation)	-40 °C ... 125 °C

### General

Note	For contact inserts HC-B16, BB32, BBB40, D40, DD72, HS6, M, K
Type	B16
Housing type	Sleeve housing
Locking type	For double locking latch
No. of cable outlets	1
Cable exit	Straight
Screw connection	none
Type of the screw connection	1x M40
Housing material	Aluminum die-cast

# Housing - HC-B 16-TFQ-H-O1STM40G - 1460157

## Technical data

### General

Housing surface material	Powder-coated, gray
--------------------------	---------------------

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440202

### ETIM

ETIM 3.0	EC000438
ETIM 4.0	EC000437
ETIM 5.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

## Approvals

### Approvals

---

#### Approvals

EAC

---

#### Ex Approvals

---

#### Approvals submitted

---

### Approval details

EAC
-----

## Housing - HC-B 16-TFQ-H-O1STM40G - 1460157

### Accessories

#### Accessories

#### Full screw connection

Cable gland - G-INS-M40-M68N-PNES-GY - 1411128



Cable gland, Cable gland material: Polyamide 6, External cable diameter 19 mm ... 28 mm, Shielding: No, Connecting thread: M40, Color: silver grey

---

Cable gland - G-INS-M40-M68N-PNES-BK - 1411137



Cable gland, Cable gland material: Polyamide 6, External cable diameter 19 mm ... 28 mm, Shielding: No, Connecting thread: M40, Color: jet black

---

Cable gland - G-INS-M40-M68N-NNES-S - 1411167



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 19 mm ... 28 mm, Shielding: No, Connecting thread: M40, Color: silver

---

Cable gland - HC-M-KV-M40(27-34) - 1607729



Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 27 ... 34 mm, WAF 50, screw connection: M40

---

Cable gland - G-INSEC-M40-M68N-NCRS-S - 1411192



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 19 mm ... 27 mm, Shielding: Yes, Connecting thread: M40, Color: silver

---

## Housing - HC-B 16-TFQ-H-O1STM40G - 1460157

### Accessories

Cable gland - HC-M-KV-Z-M40 - 1646175



Metal screw connection with strain relief clamp, thread length: 8 mm, cable sealing area: 24 - 33 mm, clamping area: 26 - 36 mm, SW 50, screw connection: M40

---

Plug for cable screw gland

Filler plugs - HC-M-BS-M40 - 1645875



Filler plug, metal, size: M40

---

Reducing adapter

Reducing adapter - REDUC-M-KV-M40/M32 - 1647640




Reducing adapter, M40 on M32, incl. O-ring

---

### Drawings

Dimensioned drawing

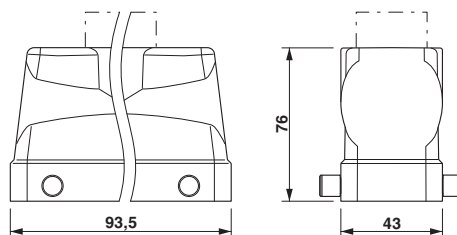

Dimensional drawing