



1000V

082 N   

UNI 7923

Wire stripper

- With screw for regulation of stripping depth
- Insulated ergonomic bimaterial grip
- Chrome plated finish

max mm ²	L mm	code	
7	170	00820003	1



1000V


083 N  

UNI 8791

Cable cutters for Copper and Aluminium cables

- Insulated ergonomic bimaterial grip
- Chrome plated finish

max mm ²	L mm	code	
17	240	00830007	1

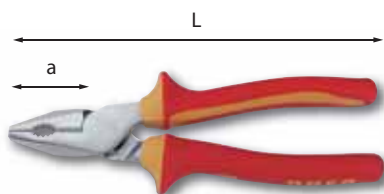

1000V


085 N   

UNI 9894 DIN ISO 5746

Combination pliers

- Model with cutter for piano wire
- Insulated ergonomic bimaterial grip
- Knurled gripping surface
- Chrome plated finish

L mm	1600 N/mm ² ø max mm	a mm	code	
160	1,6	34	00850003	1
180	1,8	36	00850004	1
200	2	42	00850005	1

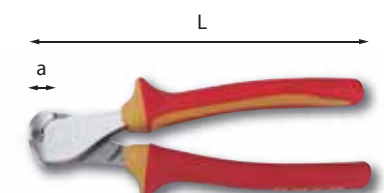

1000V


086 N   

UNI DIN ISO 5748

End cutting nippers

- Model for piano wire
- Insulated ergonomic bimaterial grip
- Chrome plated finish

L mm	1600 N/mm ² ø max mm	a mm	code	
160	1,6	6,5	00860003	1

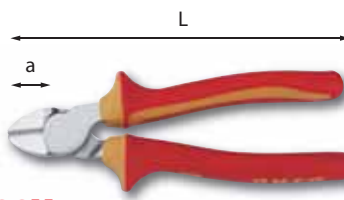

1000V


087 N   

UNI DIN ISO 5749

Diagonal cutting nippers

- Model for hard wire
- Insulated ergonomic bimaterial grip
- Chrome plated finish

L mm	1600 N/mm ² ø max mm	a mm	code	
140	1,8	15,5	00870002	1
160	2	16,5	00870003	1

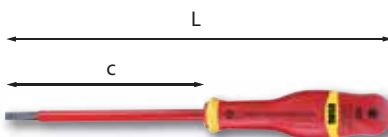

1000V

092   

UNI 10562 ISO 2380 DIN 5264

Screwdrivers for slot-head screws

- Insulated ergonomic three-material grip
- Silicon Chrome Manganese steel blade
- Phosphatised finish

axbxc mm	L mm	code	
0,4x2,5x50	144	00920003	5
0,4x2,5x75	169	00920004	5
0,5x3x75	179	00920005	5
0,6x3,5x75	179	00920006	5
0,6x3,5x100	204	00920007	5
0,8x4x100	209	00920008	5
0,8x4x125	259	00920009	5
1x5,5x125	234	00920010	5
1x5,5x150	259	00920011	5
1,2x6,5x150	270	00920012	5
1,2x8x150	275	00920013	1
1,6x10x200	325	00920014	1




1000V

092 SE4   

Set of four screwdrivers for slot-head screws

- 092/0,5x3x75-0,8x4x100-1x5,5x125-1,2x6,5x150

gr	code	
260	00920110	1

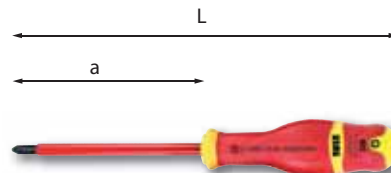

1000V


092 PH   

UNI ISO 8764 DIN 5260

Screwdrivers for PHILLIPS® screws

- Insulated ergonomic three-material grip
- Silicon Chrome Manganese steel blade
- Phosphatised finish

n°xa	L mm	code	
0x75	179	00920023	5
1x100	209	00920025	5
2x125	245	00920027	5
3x150	275	00920029	1
4x200	325	00920031	1

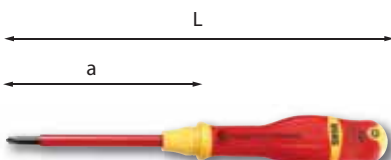

1000V

092 PHB   

Screwdrivers for slot-head/Phillips® screws

- Insulated ergonomic three-material grip
- Silicon Chrome Manganese steel blade
- Phosphatised finish

n°xa	L mm	code	
1x100	209	00920037	1
2x125	245	00920038	1




1000V

092 PHB/SE2   

Set of two screwdrivers for coupled shape

- 092 PHB/1x100-2x125

gr	code	
250	00920120	1

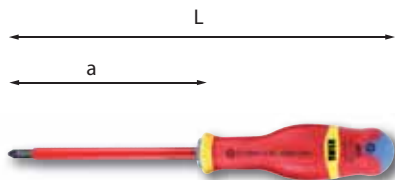

1000V


092 PZ

UNI ISO 8764 DIN 5260

Screwdrivers for POZIDRIV® - SUPADRIV® screws

- Insulated ergonomic three-material grip
- Silicon Chrome Manganese steel blade
- Phosphatised finish

n°xa	L mm	code	
0x75	179	00920040	5
1x100	209	00920042	5
2x125	245	00920044	5
3x150	275	00920046	1

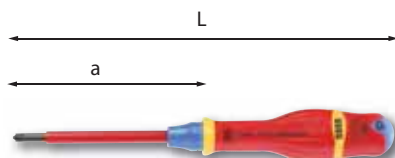

1000V

092 PZB

Screwdrivers for slot-head/POZIDRIV® - SUPADRIV® screws

- Insulated ergonomic three-material grip
- Silicon Chrome Manganese steel blade
- Phosphatised finish

n°xa	L mm	code	
1x100	209	00920052	1
2x125	245	00920054	1



1000V

092 PZB/SE2

Set of two screwdrivers for coupled shape

- 092 PZB/1x100-2x125

gr	code	
250	00920121	1



1000V

092 SH5

Set of five screwdrivers for slot-head and PHILLIPS® screws

- 092/0,5x3x75-0,8x4x100-1x5,5x125
- 092 PH/1x100-2x125

gr	code	
440	00920100	1




1000V

092 SH8

Set of eight screwdrivers for slot-head, PHILLIPS® and coupled shape screws

- 092/0,5x3x75-0,8x4x100-1x5,5x125-1,2x6,5x150
- 092 PH/0x75-1x100-2x125
- 092 PZB/2x125

gr	code	
740	00920105	1

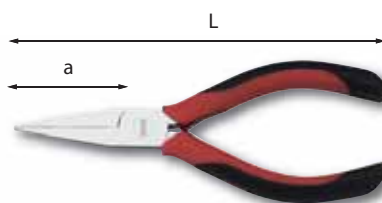


113 M

ISO 9655

Flat long nose pliers with straight jaws

- Knurled gripping surface
- Spring-action with interchangeable plates
- Ergonomic bimaterial grip
- Chrome plated finish

L mm	a mm	code	
140	41	113110	2

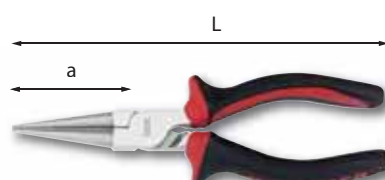


114 A

UNI 10294 DIN ISO 5745

Round long nose pliers with straight jaws

- Knurled gripping surface
- Ergonomic bimaterial grip
- Chrome plated finish

L mm	a mm	code	
160	52	114051	2

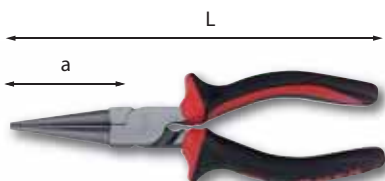


114 B

UNI 10294 DIN ISO 5745

Round long nose pliers with straight jaws

- Knurled gripping surface
- Ergonomic bimaterial grip
- Protective enamelled finish

L mm	a mm	code	
160	52	114053	2

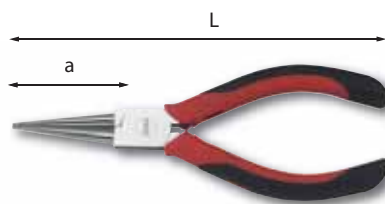


114 M

ISO 9655

Round long nose pliers with straight jaws

- Knurled gripping surface
- Spring-action with interchangeable plates
- Ergonomic bimaterial grip
- Chrome plated finish

L mm	a mm	code	
140	41	114110	2

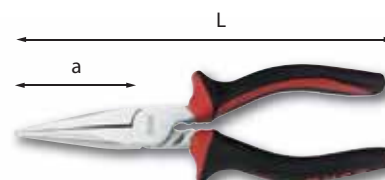

115 A

UNI 10295 DIN ISO 5745

Half-round long nose pliers with straight jaws

- Knurled gripping surface
- Ergonomic bimaterial grip
- Chrome plated finish

L mm	a mm	code	
160	52	115051	2