

## Classic ECO A55

CLECO A55 240V 70W E27 SV1

0023138



### Range features

- 1:1 replacement of Incandescent A55 lamp
- More efficient - more savings
- Excellent colour rendering (CRI = 100)
- Instant illumination
- Sparkling light output
- Less heat generation than incandescent lamp
- Less CO2 emissions
- Identical shape as standard incandescent lamp
- Commercial and domestic application
- 100% dimmable
- Average rated life 1500hrs or 2000hrs - up to two times more average life compared to incandescent lamps



### PRODUCT OVERVIEW

Ordering number	0023138
Light colour	828 Homelight
Technology	Halogen
Energy class	D
Average life (Rated) (h)	2000
Lamp finish	Clear
Lamp shape	GLS A55
Dimmable	Yes
Cap/Base	E27
Type	Classic 'A' Shape
EAN code	5410288231389
CRI (Ra)	100
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	1190
Watt (Nominal) (W)	70
Equivalent watt (W)	92
Voltage (V)	240

## Classic ECO A55

CLECO A55 240V 70W E27 SV1

0023138

### DATA TABLE

#### General data

Ordering number	0023138
Technology	Halogen
Average life (Nominal) (h)	2000
Average life (Rated) (h)	2000
Energy saving lamp	No
Energy class	D
Lamp shape	GLS A55
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E27
Type	Classic 'A' Shape
EAN code	5410288231389
E-number SE	8355977
E-number FI	4740148
Long description	1:1 replacement of Incandescent A55 lamp. More efficient - more savings. Excellent colour rendering (CRI = 100). Instant illumination. Sparkling light output. Less heat generation than incandescent lamp. Less CO2 emissions. Identical shape as standard incandescent lamp. Commercial and domestic application. 100% dimmable. Average rated life 1500hrs or 2000hrs - up to two times more average life compared to incandescent lamps
Product name	CLECO A55 240V 70W E27 SV1
Lamp mercury content (mg)	0
Starting time (max) (s)	0.01
Warm-up time to 60% of full light (max) (s)	Instant full light
Control gear required	No
Fixture rating	Open
IEC Reference	IEC 60357
IEC Reference 2	IEC 60432-2
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	> 8000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

## Classic ECO A55

CLECO A55 240V 70W E27 SV1

0023138

### Optical data

Light colour	828 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	1190
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	1190

### Electrical data

kWh per 1000 hours burning time	70
Watt (Rated) (W)	70
Watt (Nominal) (W)	70
Equivalent watt (W)	92
Voltage (V)	240
Lamp power factor	1

### Physical data

Weight (kg)	0.03
Lamp Length (mm) - C/L	100
Max. Lamp Diameter (mm) - D	56
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	9.60 x 5.50 x 5.50
Inner package dimensions (L x W x H) (cm)	28.00 x 11.00 x 10.00
Inner package net weight (kg)	0.28
Outer package dimensions (L x W x H) (cm)	59.00 x 30.50 x 22.50


## Classic ECO A55

CLECO A55 240V 70W E27 SV1


0023138

### TECHNICAL DRAWINGS

Classic ECO A55

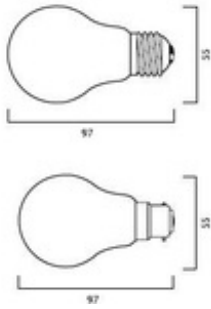

E27

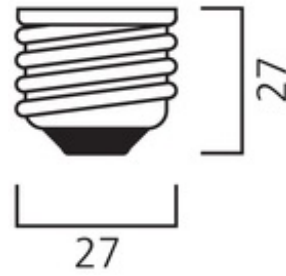

### ENERGY LABEL

