



ACR Indust COG HT200C, Ceramic, 150 pF, 10%, 100 VDC, COG, Commercial, High Temperature, Lead Spacing = 5.08mm

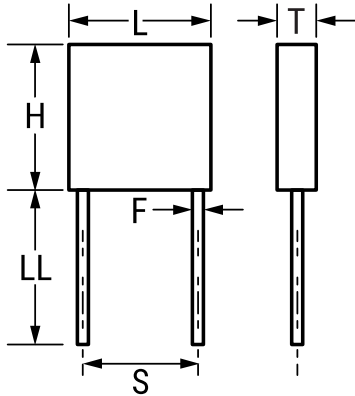

Dimensions	
L	5.08mm MAX
H	5.08mm MAX
T	2.54mm MAX
S	5.08mm +/-0.38mm
LL	31.75mm MIN
F	0.508mm +/-0.051mm

Packaging Specifications	
Packaging:	Bulk, Bag
Packaging Quantity:	1

General Information	
Supplier:	KEMET
Series:	ACR Indust COG HT200C
Style:	Radial
Description:	Commercial, High Temperature
Features:	Commercial
RoHS:	No
Prop 65:	 WARNING: Cancer and reproductive harm - www.p65warnings.ca.gov
REACH:	SVHC (Pb – CAS 7439-92-1)
Termination:	Gold
Failure Rate:	N/A
Testing and Reliability:	Standard

Specifications	
Capacitance:	150 pF
Capacitance Tolerance:	10%
Voltage DC:	100 VDC
Dielectric Withstanding Voltage:	250 VDC
Temperature Range:	-55/+200°C
Temperature Coefficient:	COG
Dissipation Factor:	0.15%
Insulation Resistance:	100 GOhms

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.