


Part Number: 8R4J30E03C3003

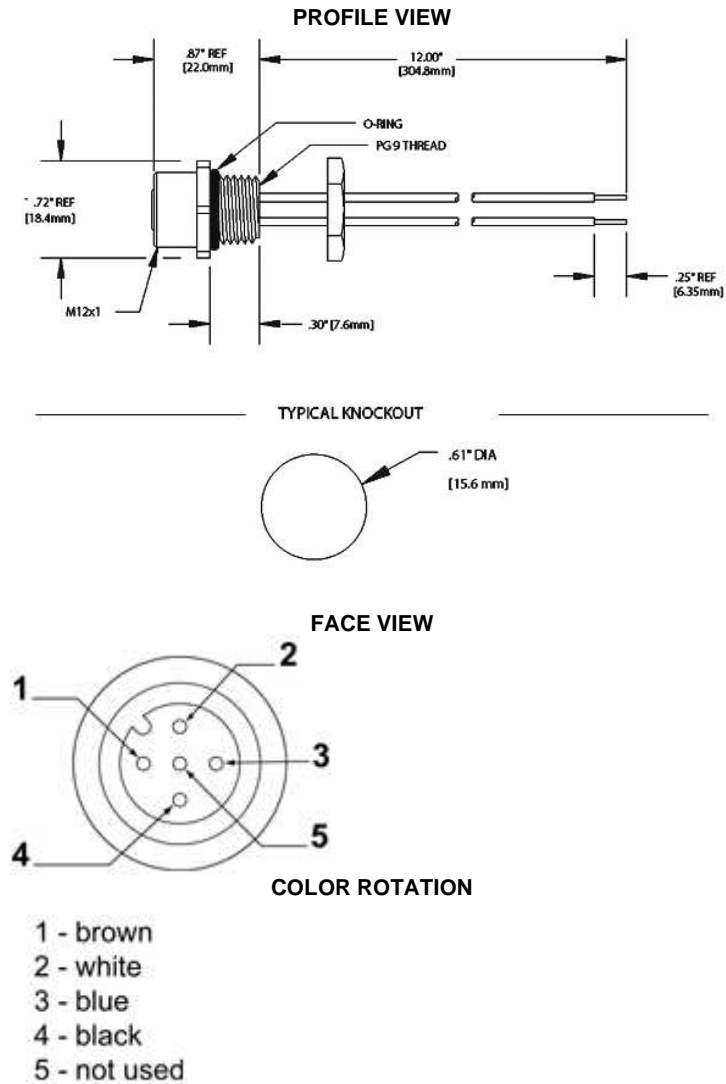

SPECIFICATIONS

Mechanical

Contact Carrier - Polyurethane (PUR)
 Socket Contact - Copper Alloy
 Contact Plating - Gold over nickel
 O-ring - Viton
 Receptacle Shell - Nickel plated brass
 Wire - #22AWG (.34mm²) PVC 80C

Electrical

Voltage Rating - 250V AC/DC
 Amperage - 4A

Environmental

Protection - IP68, NEMA 6P
 Ambient Operating Temperature - -20C to 90C