



Datasheet

Stock No: 748-2106

ENGLISH

RS Pro Yellow Equipment Wire, 1 mm² CSA, 1500 V 6 A 17 AWG, 500m



BS 4808

Cable Construction

Conductor

square(mm²)

Construction

Standard Dia.(mm)

Insulation

Thickness

Insulation Dia.(±0.15mm)

Tinned Copper

1.0

T0.2±0.008×32


1.30

PVC

0.6

2.52 +0.13/-0.12

Design

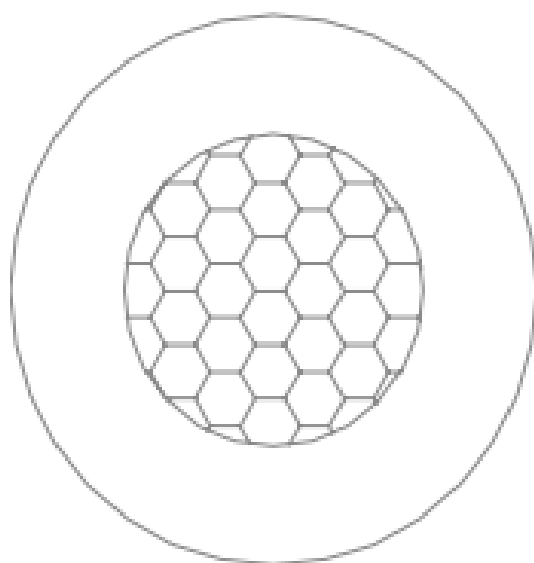

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<18.8
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1500