
PARATHOM CLASSIC A 75 ADV 11 W/827 E27

PARATHOM CLASSIC A advanced | Dimmable LED lamps, classic bulb shape, with retrofit screw base



Areas of application

- Domestic applications
- General illumination
- Outdoor use in outdoor luminaires only (minimum IP65)

Product benefits

- Very low energy consumption
- Robust against vibrations
- Extremely long life
- No UV and near-IR radiation in the light beam
- Instant 100 % light, no warm-up time
- Can be easily fitted instead of ordinary light bulbs
- Lower thermal output (compared with the standard reference product)
- Correct operation even at low temperatures

Product features

- Professional LED lamps for line voltage
- Dimmable (with many common dimmers, see also www.osram.com/dim)
- Base: E27
- Mercury-free lamps



Technical data

Electrical data

| | |
|--|------------|
| Rated wattage | 11.00 W |
| Nominal wattage | 11.00 W |
| Nominal voltage | 230.00 V |
| Operating frequency | 50...60 Hz |
| Power factor λ | 0.95 |
| Claimed equiv. conventional lamp power | 75 W |


Photometrical data

| | |
|--|---------------------------|
| Nominal luminous flux | 1055 lm |
| Rated luminous flux | 1055 lm |
| Color temperature | 2700 K |
| Color rendering index Ra | >80 |
| Lumen main.fact.at end of nom.life time | 0.70 |
| Light color as per EN 12464-1 | Warm White |
| Standard deviation of color matching | ≤ 6 sdc _m |
| Lumen maintenance at end of service life | 0.70 |

Light technical data

| | |
|---------------------|--------|
| Warm-up time (60 %) | 0.20 s |
| Starting time | 0.2 s |

Dimensions & weight

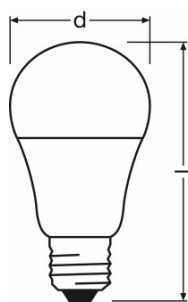

| | |
|----------------|----------|
| Overall length | 110.0 mm |
| Diameter | 60.0 mm |
| Outer bulb | A65 |
| Length | 110.0 mm |

Product datasheet

Lifespan

| | |
|----------------------------|---------|
| Nominal lamp life time | 20000 h |
| Rated lamp life time | 20000 h |
| Number of switching cycles | 100000 |

Additional product data

| | |
|-----------------------------------|--|
| Base (standard designation) | E27 |
| Lamp mercury content | 0.0 mg |
| Mercury-free | Yes |
| New article | NEW |
| Design / version | Frosted |
| Appropriate disposal acc. to WEEE | Yes |
| Footnote only for product | All technical parameters apply to the entire lamp/Due to the complex production process for light-emitting diodes, the typical values shown for the technical LED parameters are purely statistical values that do not necessarily match the actual technical parameters of each individual product, which can vary from the typical value/In development, data preliminary/In preparation/LED lamps contain several electronic components. Under unfavourable conditions these can lead to acoustic noise. In case of resonance even low noise can cause audible effect. Possible factors influencing this are the installation, the design of the lamp holder and the luminaire (acoustic resonance effect) as well as the dimmer or the transformer (harmonics or electronic resonance) |

Capabilities

| | |
|----------|-------------------|
| Dimmable | Yes ¹⁾ |
|----------|-------------------|

¹⁾ With many common dimmers, see also www.osram.com/dim

Certificates & standards

| | |
|-------------------------|--------------|
| Energy efficiency class | A+ |
| Energy consumption | 11 kWh/1000h |

Country specific categorizations

| | |
|-----------------|----------------------------|
| ILCOS | DRAA/F-13,5/827-230-E27-60 |
| Order reference | PCLA75ADV 11W/8 |

Product datasheet



Guarantee

Logistical Data

| Product code | Product description | Packaging unit (Pieces/Unit) | Dimensions (height x width x length) | Volume | Gross weight |
|---------------|--|------------------------------|--------------------------------------|----------------------|--------------|
| 4052899924772 | PARATHOM CLASSIC A 75 ADV 11 W/827 E27 | Shipping carton box 10 | 131 mm x 137 mm x 324 mm | 5.81 dm ³ | 1570.00 g |

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

For dimming conformity see

▶ www.osram.com/DIM

For further products and actual information concerning LED lamps see

▶ www.osram.com/ledlamps

For Guarantee see

▶ www.osram.com/guarantee

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.