


DUO PACK

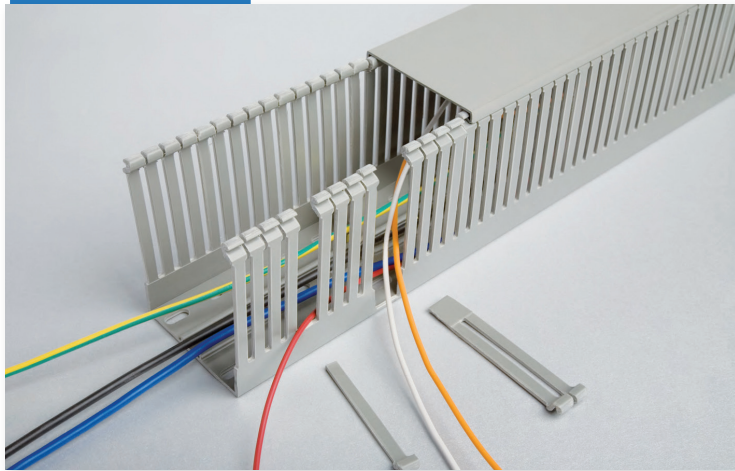


Betaduct PVC metric narrow open slot provides lightweight self-extinguishing cable trunking with excellent rigidity and performance characteristics. Its restricted slot design, enables the wire to be retained in the slot.


Supplied in handy duo packs containing 2x2 meter lengths.

Recommended fixing method - Betaduct rivets. Supplied with lid.

Side Slot Design

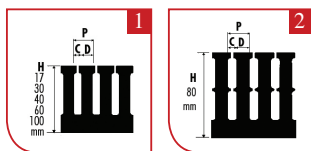

Base Hole Design

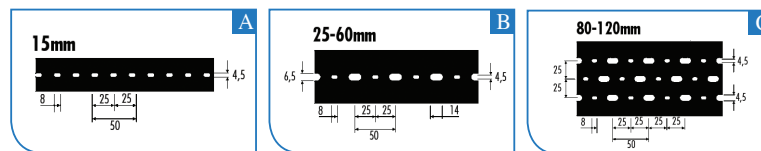

Specification:

Material: Self-extinguishing PVC

Slot Pitch: 20mm

Slot Width: 8mm

Webs: 12mm

Flammability: UL94 V-0 Rated material

Service temperature rating: 15°C to + 60°C

Standards: RoHS 2 compliant, UL94 V-0, A Norme EN50085-2-3, CSA, UR, RINA, CE marked

Part Numbers:

RS PART NO.	BETADUCT PART NO.	EXTERNAL SIZE WxH (mm)	USABLE SECTION (mm ²)	BASE HOLE DESIGN	SIDE SLOT DESIGN	C	D	P	PACK QUANTITY METRES
8781114	10440064	60 x 80	4200	B	2	4	6	10	2 x 2m
8802081	10440084	80 x 80	5695	C	2	4	6	10	2 x 2m