



For new constructions:
Series "E2/000"
2400/2500 ▶ page 5.84

Series 200 · 240 · 250 E2 medium

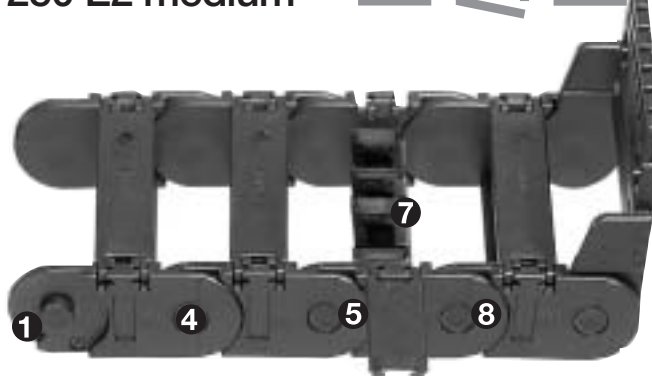





- 1 Double stop dog for long unsupported length
- 2 Snap-open, hinged to left or right, accessible from the top
- 3 Integrated strain relief possible
- 4 Large pins for long service life
- 5 Lateral glide surfaces for side-mounted operation
- 6 Tapered insertion point for easy assembly
- 7 Cable-friendly, smooth interior with modular interior separation
- 8 Dirt-repellent, contoured exterior
- 9 Series 240 snap-open along inner radius can be combined with Series 250 snap-open along outer radius

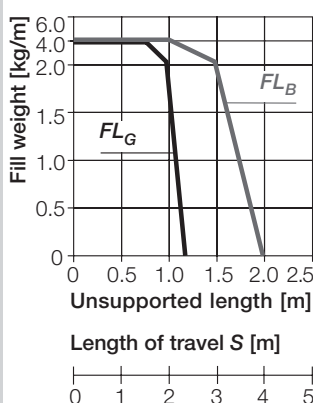

Unsupported length

FL_G = with straight upper run

FL_B = with permitted sag

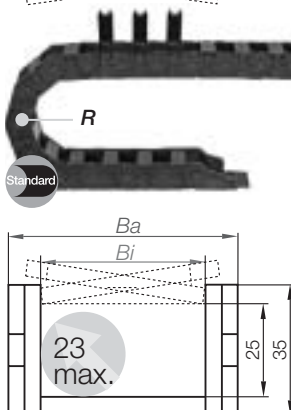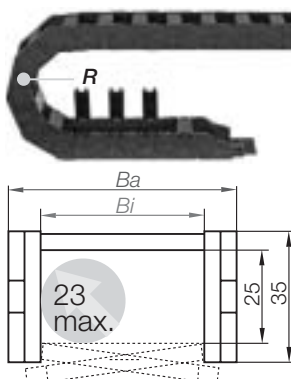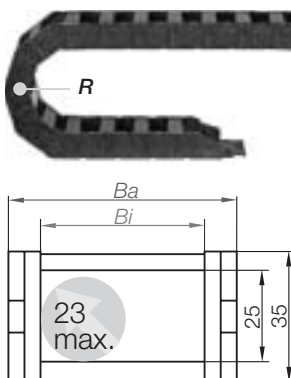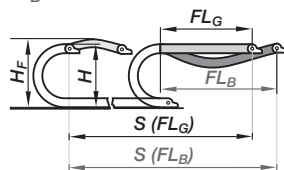

Series 200 - non snap-open

Part No.	Bi [mm]	Ba [mm]	R [mm] Bending Radii
200.02.□.0	25	41	055 075 100
200.03.□.0	38	54	125 150 175
200.05.□.0	57	73	200 225 250
200.07.□.0	77	93	
200.09.□.0	90	106	
200.10.□.0	103	119	
200.12.□.0	125	141	

Radii for all widths!

Supplement Part No. with required radius. Example: 200.10.100.0

Bending radii listed above can be combined with every chain width!

Series 240 - snap-open along inner radius

Part No.	Bi [mm]	Ba [mm]	R [mm] Bending Radii
240.02.□.0	25	41	055 075 100
240.03.□.0	38	54	125 150 175
240.05.□.0	57	73	200 225 250
240.07.□.0	77	93	
240.09.□.0	90	106	
240.10.□.0	103	119	
240.12.□.0	125	141	

Radii for all widths!

Supplement Part No. with required radius. Example: 240.10.100.0

Bending radii listed above can be combined with every chain width!

Series 250 - snap-open along outer radius

Part No.	Bi [mm]	Ba [mm]	R [mm] Bending Radii
250.02.□.0	25	41	055 075 100
250.03.□.0	38	54	125 150 175
250.05.□.0	57	73	200 225 250
250.07.□.0	77	93	
250.09.□.0	90	106	
250.10.□.0	103	119	
250.12.□.0	125	141	

Radii for all widths!

Supplement Part No. with required radius. Example: 250.10.100.0

Bending radii listed above can be combined with every chain width!

Part No. structure



250. 10. 100.0

Color
black

Bending radius

Width

Series



Order example 2,0 m complete E-Chain®

(Indicate chain-lengths or number of links)

2,0 m (44 links) **Series 250.10.100.0**

+ 2 separators **211** assembled each 2nd link

+ 1 set mounting brackets + tie-wrap plates **2100.34PZB**

Series 200 · 240 · 250 E2 medium


igus.de

200
240
250
E2 medium


Pitch = 46 mm Links per m = 22 Chain length = $S/2 + K$

R	055	075	100	125	150	175	200	225	250
H ⁺ 4	145	185	235	285	335	385	435	485	535
D	125	150	170	195	220	245	270	295	320
K	276	346	414	496	578	660	742	814	920

The required clearance height is $H_F = H + 25$ mm (with 1,5 kg/m fill weight). Please consult igus® if space is particularly restricted.

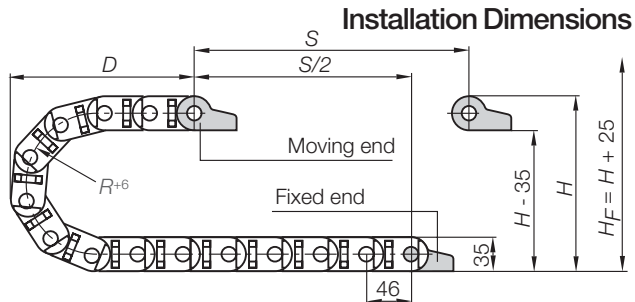


Installation Dimensions

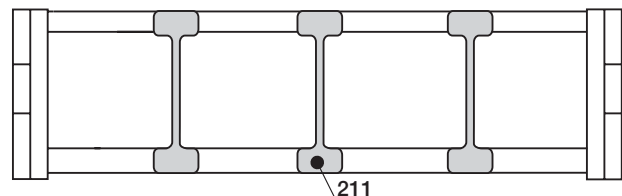

Vertical Separator

unassembled	201
assembled	211

 

Interior Separation

(the complete range ► 5.84)




2...3PZ(B)

Moving end


2...4PZ(B)

Fixed end

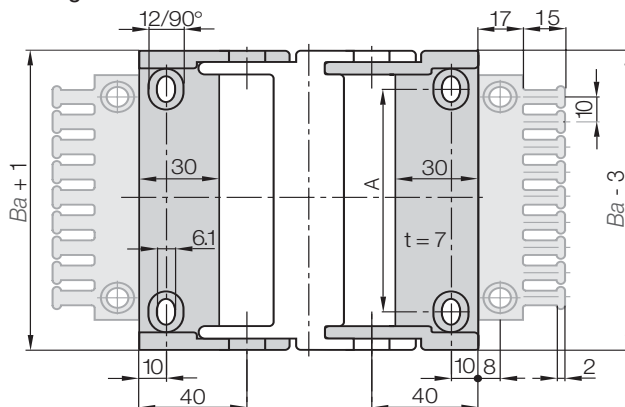


Moving end (with bore)

2...3PZ(B)

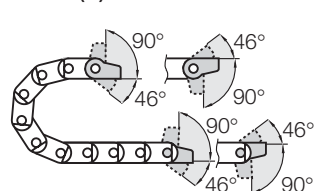

2...4PZ(B)
Fixed end (with pin)

Mounting Brackets

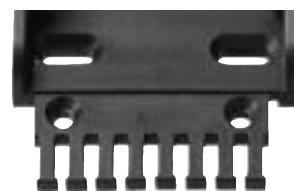

Polymer pivoting, with or without strain relief tiewrap plates

For E-Chain®	Part No. full set with tiewrap plate	Part No. with tiewrap plate + 10 cable tiewraps	Part No. full set without tiewrap plate	Dimension A [mm]
200/240/250.02. ►	2020.34PZB	2020.34PZBK1	2020.34PZ	12
200/240/250.03. ►	2030.34PZB	2030.34PZBK1	2030.34PZ	25
200/240/250.05. ►	2050.34PZB	2050.34PZBK1	2050.34PZ	44
200/240/250.07. ►	2070.34PZB	2070.34PZBK1	2070.34PZ	64
200/240/250.09. ►	2090.34PZB	2090.34PZBK1	2090.34PZ	77
200/240/250.10. ►	2100.34PZB	2100.34PZBK1	2100.34PZ	90
200/240/250.12. ►	2125.34PZB	2125.34PZBK1	2125.34PZ	112

Tiewrap plates are possible at the moving end and/or the fixed end!

Part No. structure

2020.34PZ	B
-----------	---

Full set with tiewrap plate
Full set without tiewrap plate

Full set, for both ends:
2020. 34 PZB (+ tiewrap plates)

Single-part order:
2020. 3 PZB (+ tiewrap plates)

Mounting bracket with bore
2020. 4 PZB (+ tiewrap plates)

Mounting bracket with pin



Interior separation with full-width shelves and shelves possible



Polymer mounting bracket, locking



KMA mounting bracket available with C-profile



Steel mounting bracket available

Additional Features

For more features
► see link below



E2 medium classic
Inner height: 25 mm

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222



► chapter 10



► chapter 9