


xzcp1965I5

pre-wired connectors XZ - elbowed female - 1/2"20 UNF - 3 pins - cable PUR 5m

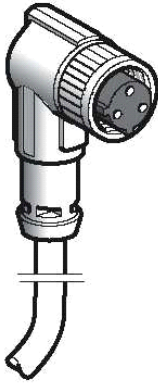

Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Pre-wired connectors
Series name	General purpose
Electrical connection	Elbowed female connector 1/2"20 UNF, 3 pins
Collar material	Metal
Status LED	Without
Cable length	5 m

Complementary

Cable connector fixing	Screw-on
Cable outer diameter	5.2 mm
Cable composition	3 x 0.34 mm ²
Wire insulation material	PUR
[Ue] rated operational voltage	250 V AC 300 V DC
[In] rated current	4 A
Contact resistance	<= 5000 μOhm
Insulating resistance	>= 1 GΩ
Product weight	0.18 kg

Environment

IP degree of protection	IP67
Ambient air temperature for operation	-35...90 °C (static) -5...90 °C (flexing)
Ambient air temperature for storage	-35...100 °C

Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS	Compliant - since 0649 - Schneider Electric declaration of conformity

The information provided in this documentation contains general descriptions and/or technical characteristics of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.