

## Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

### Range features



CE

### PRODUCT OVERVIEW

Ordering number	0035134
Technology	Compact Fluorescent
Light colour	827 Homelight
Energy class	A
Average life (Rated) (h)	10000
Lamp shape	Stick
Lamp finish	frosted
Dimmable	No
Cap/Base	E14
Type	Mini-Lynx Fast Start T3 3U Stick
EAN code	5410288351346
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	450
Efficacy (Rated) (lm/w)	56.25
Watt (Nominal) (W)	8
Equivalent watt (W)	42
Voltage (V)	230-240

# Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

## DATA TABLE

### General data

<b>Ordering number</b>	0035134
<b>Dry applications use only</b>	Yes
<b>Technology</b>	Compact Fluorescent
<b>Average life (Rated) (h)</b>	10000
<b>Average life (Nominal) (h)</b>	10000
<b>Energy class</b>	A
<b>Energy saving lamp</b>	Yes
<b>Lamp shape</b>	Stick
<b>Lamp finish</b>	frosted
<b>Dimmable</b>	No
<b>Cap/Base</b>	E14
<b>Type</b>	Mini-Lynx Fast Start T3 3U Stick
<b>EAN code</b>	5410288351346
<b>E-number FI</b>	4940292
<b>E-number SE</b>	8357532
<b>Long description</b>	
<b>Product name</b>	ML FAST-START 827 E14 8W SLV
<b>Lamp mercury content (mg)</b>	<2.5
<b>Starting time (max) (s)</b>	< 1.50 Sec
<b>Warm-up time to 60% of full light (max) (s)</b>	< 40 s
<b>Control gear required</b>	No
<b>IEC Reference</b>	IEC 60968
<b>IEC Reference 2</b>	IEC 60969
<b>IEC Reference 3</b>	IEC 55015
<b>ILCOS code</b>	FBTH-08/27/1b-E14-44/112
<b>Intended purpose</b>	General lighting
<b>No. of switching cycles before premature failure (min)</b>	30000
<b>Special purpose lamp</b>	No
<b>Transformer required</b>	No
<b>Sales pack quantity</b>	10
<b>Optimal operating condition (°C)</b>	25° C, cap-up, Stated lumen output may vary if operated in non-standard position

## Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

### Optical data

Light colour	827 Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Lumen maintenance at end of nominal life (%)	= 75.0 %
Luminous flux (Nominal) (lm)	450
Luminous flux (Rated) (lm)	450
Chromaticity coordinate X	0.463
Chromaticity coordinate Y	0.42
Rated lumen maint. factor at 6000 h	= 80.0 %

### Electrical data

kWh per 1000 hours burning time	8
Efficacy (Rated) (lm/w)	56.25
Watt (Nominal) (W)	8
Watt (Rated) (W)	8
Equivalent watt (W)	42
Voltage (V)	230-240
Current (A)	0.07
Lamp power factor	> 0.55

### Physical data

Weight (kg)	0.06
Lamp Length (mm) - C/L	112
Max. Lamp Diameter (mm) - D	44
Single packaging type	Box/Sleeve
Single package dimensions (L x W x H) (cm)	12.00 x 4.50 x 4.50
Inner package dimensions (L x W x H) (cm)	24.00 x 15.00 x 10.40
Inner package net weight (kg)	0.56
Outer package dimensions (L x W x H) (cm)	25.00 x 16.50 x 54.50


## Mini-Lynx Fast-Start

ML FAST-START 827 E14 8W SLV

0035134

### TECHNICAL DRAWINGS

---

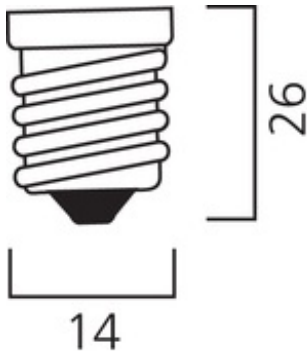

### ENERGY LABEL

---

