

EM 231



Euromas II
 Enclosure, polycarbonate

Order no.: 62231000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request


Protection class

IP 65/DIN EN 60529; higher ingress protection on request

Enclosure material

ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information

Scope of delivery: Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

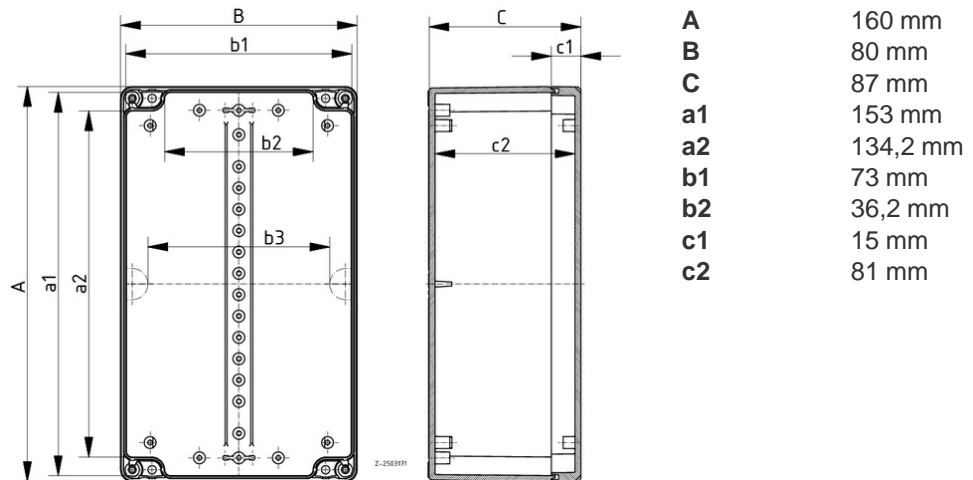

Technical drawings

Catalogue drawing in DXF format:

[62231000_EM-231.dxf](#) (0.9 MB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[62231000_EM-231-G.dxf](#) (446 KB)

Catalogue drawing in PDF format:

[62231000_EM-231.pdf](#) (100 KB)

Chapter download

[Euromas_II_GB.pdf](#) (362 KB)

Accessories



Rubber feet, self-adhesive

22009000 [GF](#)

Polyurethane, 65-75 Shore Black



Wall brackets, screw-on at rear

22010000 [EM-WL](#)



Screw covers

22080000 [EM-SA](#)



Mounting panels, laminated paper

22000600 [M](#)

For EM/ET 220, EM/ET 231, M/T 219-220, M/T 231-235



DIN rail acc. to DIN EN 60715 TH 15

22151501 [TS 15](#)

For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



DIN rail acc. to DIN EN 60715 G 32

22321501 [TS 32](#)

For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..



DIN rail acc. to DIN EN 60715 TH 35

22351501 [TS 35](#)

For EM/ET 220, EM/ET 229-231, EM/ET 238, B



1808.., B 1813..

* = Available on request