

# Panel mounting frames - VS-PPC-F1-SCRJ-MNNA-1RF - 1405374


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



SCRJ panel mounting frame, IP67, for push/pull interlocking, metal, with the Freenet system, for square mounting cutout, with seal and SCRJ coupling, without mounting screws



## Key commercial data

Packing unit	1 pc
GTIN	 4 046356 419925
Weight per Piece (excluding packing)	37.4 g
Custom tariff number	85389099
Country of origin	Germany

## Technical data

### Mechanical characteristics

Color	silver
-------	--------

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
Degree of protection	IP65/67

### Material data

Housing material	Zinc die-cast
------------------	---------------

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27261207
eCl@ss 7.0	27440210

# Panel mounting frames - VS-PPC-F1-SCRJ-MNNA-1RF - 1405374

## Classifications

eCl@ss

eCl@ss 8.0	27440210
------------	----------

## ETIM


ETIM 3.0	EC002310
ETIM 4.0	EC002310
ETIM 5.0	EC002310

## UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501


## Drawings

Dimensioned drawing

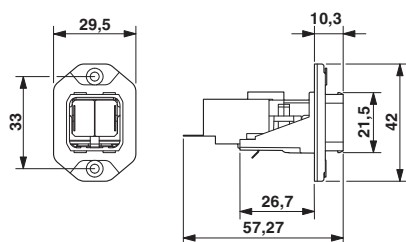

Push-Pull SCRJ panel mounting frame

Dimensioned drawing

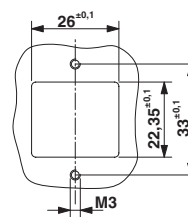

Panel cutout

Explosion drawing

