

# CLASSIC series

## Stylish Yet Familiar

A revolutionary breakthrough in both size and durability, the MEGAMAN® CLASSIC series delivers a classic feel that allows you to use it in almost any light fitting of your choice.



## PING-PONG CLASSIC




Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
191123	E27	45	74	44
101402	B22	45	73	44
181124	E14	45	83	41

### GA807i

7 Watt
15,000 hours
286lm
Standard Pack 60 (10)
Colour Temp WARM WHITE

**Description:** Ping-Ping Ball shape with Translucent Housing.

### Product Features

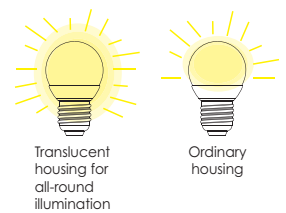


Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
903048	E27	55	102	64
903086	E14	55	102	64
903123	B22	55	100	64

### GA911i

11 Watt
15,000 hours
570lm
Standard Pack 60 (10)
Colour Temp WARM WHITE

**Description:** Ping-Ping Ball shape with Translucent Housing.

GA807i      Incandescent P45  
GA911i

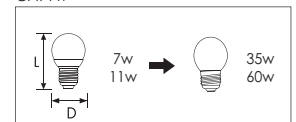

- 15,000 hrs lifetime
- 600,000 switching cycles
- shorter preheating time




Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
190027	E27	45	87	52

## GA604

**Description:** Golf Ball shape with Translucent Housing.

### Product Features


IP55 protection is guaranteed when used with proper lamp holder of IP44 or above

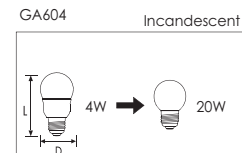

Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
190126	E27	45	86	49
940035	E14	45	90	43
192120	B22	45	86	49

## GA707i


**Description:** Golf Ball shape with Translucent Housing.

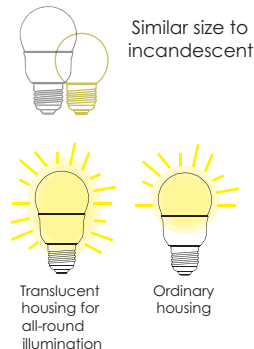

Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
940066	E27	45	95	55
192229	B22	45	95	55

## GA709i

**Description:** Miniature GLS shape with Translucent Housing.

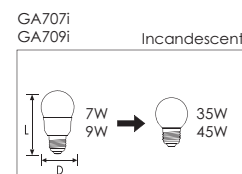

- 15,000 hrs lifetime
- 600,000 switching cycles
- shorter preheating time




GSU111i

Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
940431	E27	60	113	80
940486	B22	60	113	80

11Watt    15,000 hours    570lm    Standard Pack 60 (10)    Colour Temp WARM WHITE    Energy A


Product Features

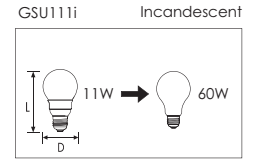

GSU520

Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
210176	E27	65	158	134
017225	B22	65	159	134

20Watt    12,000 hours    1151lm    Standard Pack 60 (10)    Colour Temp WARM WHITE    Energy A

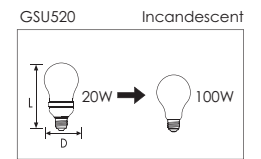


GSU420

Order Code	Lamp Base	Diameter (mm)	Length (mm)	Weight (g)
933205	E27	98	149	218
941377	B22	98	149	218

20Watt    10,000 hours    1000lm    Standard Pack 24 (6)    Colour Temp WARM WHITE    Energy A

Product Features

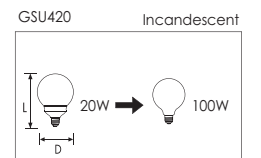

- 15,000 hrs lifetime
- 600,000 switching cycles
- shorter preheating time