


P409, Film, Metallized Paper, Resistor/Capacitor, 0.47 uF, 20%, 630 VDC, 85°C, Lead Spacing = 25.4mm

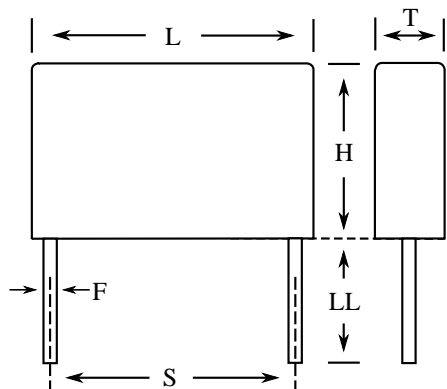

Dimensions

L	30.5mm MAX
H	22mm MAX
T	15.3mm MAX
S	25.4mm +/-0.4mm
LL	30mm +5mm
F	1mm +/-0.05mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	75

General Information

Supplier:	KEMET
Series:	P409
Dielectric:	Metallized Paper
Style:	Radial
Features:	RC Unit approved
RoHS:	Yes
Lead:	Wire Leads
Qualifications:	ENEC, UL, cUL
Construction:	Molded
Miscellaneous:	Resistor Tolerance: +/-30%. Resistor= 68 Ohms

Specifications

Capacitance:	0.47 uF
Capacitance Tolerance:	20%
Voltage AC:	275 VAC
Voltage DC:	630 VDC
Temperature Range:	-40/+85C
Rated Temperature:	85°C
Insulation Resistance:	2.128 GOhms
Safety Class:	X2