

Product Female cable connector moulded-on cable  
Area Snap-in connectors IP 40


serie 709

Pole 4  
Article number 79 9004 12 04

illustration



scale drawing

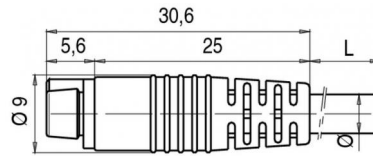

Contact Arrangement



1 braun  
2 weiß  
3 blau  
4 schwarz

Technical data

Common values

Connector Design	Female cable connector
Connector locking system	Snap-in locking
Termination	moulded on cable
Wire gauge (mm)	0,25 mm <sup>2</sup>
Wire gauge (AWG)	24
Max. Cable outlet	-
Upper temperature	+70 °C
Lower temperature	-20 °C

Electrical values

Rated voltage	60 V
Rated impulse voltage	800 V
Pollution degree	I
Overvoltage category	II
Material group	III
Rated current (40°C)	3 A
Volume resistivity	≤ 3 mΩ
EMV compliance	not shielded
Degree of protection	IP 40
Mechanical operation	>100 mating cycles

Material

Material of contact	CuSn (bronze)
Contact plating	Au (gold)
Material of contact body	PA
Material of housing	PUR

Cable data

material housing	PVC
insulation single lead	PVC
single lead structure	32 x 0,10 mm
cable sheath Ø	4.5
conductor resistance	80Ω/Km (20°C)
bending radius cable fixed	22 mm
bending radius cable movable	45 mm
cable diameter	4.5

Contacts 4, Female cable connector  
moulded-on cable, Cable length 2 m

