

M 210



Euromas
Enclosure, polycarbonate

Order no.: 02210000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request

Protection class

Depending on the model: IP 65 or IP 66/DIN EN 60529; IP 67 available on request for some sizes.


Enclosure material

ABS, PC (UV stabilised) and selected sizes in PC UL 94 V0 (additional UL 94 V0 versions on request), seal made of CR; for details see Technical Information

Scope of delivery: Lid and base, lid screws made of V2A, self-tapping screws for mounting bosses

Note: G = Design with crystal-clear lid.

IP = Ingress protection acc. to DIN EN 60529

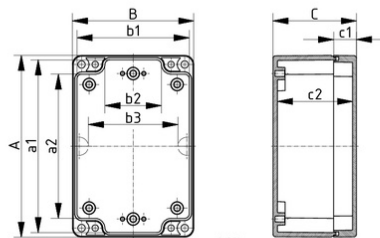

A	82 mm
B	80 mm
C	55 mm
a1	75,3 mm
a2	56,6 mm
b1	73,3 mm
b2	36,5 mm
c1	15 mm
c2	49 mm

Technical drawings

3D product data in STEP format:

[Registration necessary](#)

Catalogue drawing in DXF format:

[02210000_M-210.dxf](#) (669 KB)

Basic drawing for processing work:

[02210000_M-210-G.dxf](#) (327 KB)

Catalogue drawing in PDF format:

[02210000_M-210.pdf](#) (88 KB)

Chapter download

[Euromas_ABS_PC_GB.pdf](#) (338 KB)

Accessories



Mounting plates, laminated paper (Pertinax), galvanised steel for version 260

22000300

[M](#)

For EM/ET 210, EM/ET 225, M/T 210, M/T 225



Knurled screws

22003100

[RD](#)

For M/T 210-215, M/T 217, M/T 220-227, M/T 231



Rubber feet, plug-in

22003300

[F](#)

For M/T 208-260



Silicone seal for lid

22003500

[SIL](#)

For M/T 210, M/T 225



Wall brackets on rear, screw-on, polycarbonate

22004900

[WL](#)

For M/T 210-243, M/T 246-253



DIN rails DIN EN 60715 TH 15

22001700

[TS 15](#)

For M/T 210, M/T 225



DIN rails DIN EN 60715 G 32

22001701

[TS 32](#)


For M/T 210, M/T 225, P 305, P 326



DIN rails DIN EN 60715 TH 35

22001702 [TS 35](#)

For M/T 210, M/T 225, P 305, P 326

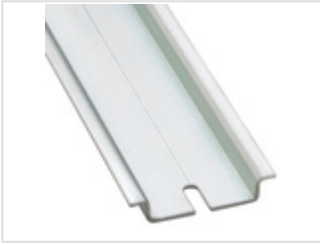

Threaded inserts for mounting bosses

59002810 [DODGE M3x6,5](#) ND = 4.0 x 6.5
59002820 [DODGE M4x9,5](#) ND = 5.4 x 9.5



* = Available on request