
 


Nova I

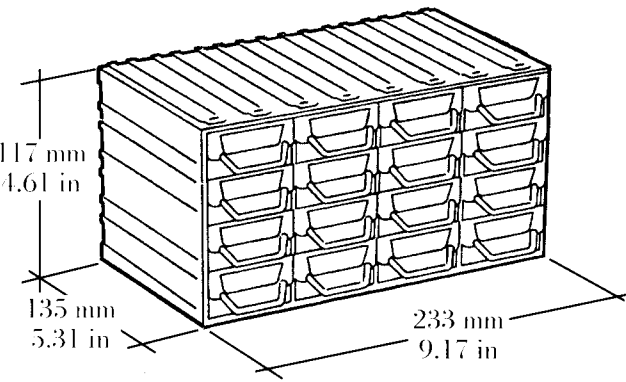

0.815

Colori/Colours/Coloris/Farben/Colores
A




16 x **XxZxY:** 48x116x22 mm
1.89x4.57x0.87 in

Colori cassetto/Colours drawer/Coloris tiroir
Farben Schublade/Colores cajon
V

 
		L x P x H			PZ x	MC	KG
IMB	mm	480	295	250	8	0.0354	6.900
	in	18.9	11.6	9.8			
Master B	mm	600	800	970	96	0.4656	81.940
	in	23.62	31.50	38.19			
Master C	mm	1200	800	970	228	0.9312	189.820
	in	47.24	31.50	38.19			
Master D	mm	600	800	1000	96	0.4800	85.740
	in	23.62	31.50	39.37			
Cont 20 FT*					6304		
Cont 40 FT*					12880		
HICUBE *					13008		

Nova 2

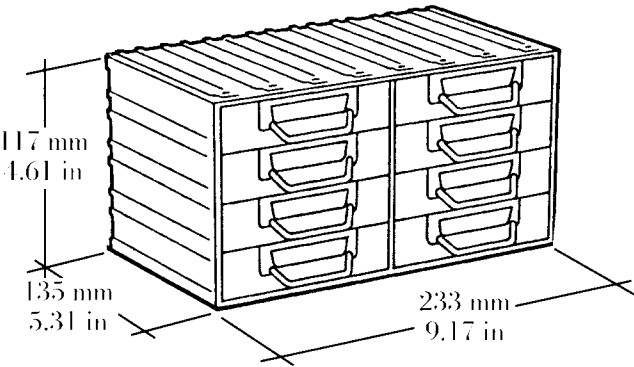

0.630

Colori/Colours/Coloris/Farben/Colores
A




8 x **XxZxY:** 106x116x22 mm
4.17x4.57x0.87 in

Colori cassetto/Colours drawer/Coloris tiroir
Farben Schublade/Colores cajon
V

 
		L x P x H			PZ x	MC	KG
IMB	mm	480	295	250	8	0.0354	5.400
	in	18.9	11.6	9.8			
Master B	mm	600	800	970	96	0.4656	64.180
	in	23.62	31.50	38.19			
Master C	mm	1200	800	970	228	0.9312	147.640
	in	47.24	31.50	38.19			
Master D	mm	600	800	1000	96	0.4800	67.980
	in	23.62	31.50	39.37			
Cont 20 FT*					6304		
Cont 40 FT*					12880		
HICUBE *					13008		

Nova 3

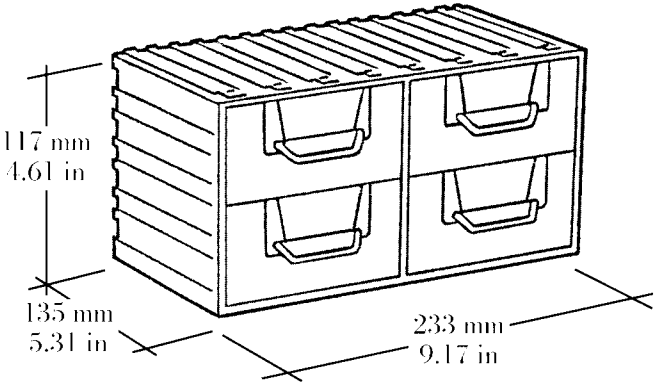

0.535

Colori/Colours/Coloris/Farben/Colores
A




4 x **XxZxY:** 106x116x48 mm
4.17x4.57x1.89 in

Colori cassetto/Colours drawer/Coloris tiroir
Farben Schublade/Colores cajon
V

 
		L x P x H	PZ x	MC	KG
IMB	mm	480 295 250	8	0.0354	4.650
	in	18.9 11.6 9.8			
Master B	mm	600 800 970	96	0.4656	55.060
	in	23.62 31.50 38.19			
Master C	mm	1200 800 970	228	0.9312	125.980
	in	47.24 31.50 38.19			
Master D	mm	600 800 1000	96	0.4800	58.860
	in	23.62 31.50 39.37			
Cont 20 FT*			6304		
Cont 40 FT*			12880		
HICUBE *			13008		

Nova 4

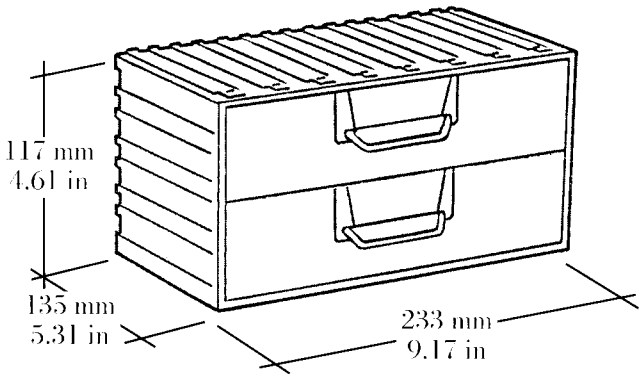

0.475

Colori/Colours/Coloris/Farben/Colores
A



2 x **XxZxY:** 220x116x48 mm
8.66x4.57x1.89 in

Colori cassetto/Colours drawer/Coloris tiroir
Farben Schublade/Colores cajon
V

		L x P x H	PZ x	MC	KG
IMB	mm	480 295 250	8	0.0354	4.175
	in	18.9 11.6 9.8			
Master B	mm	600 800 970	96	0.4656	49.300
	in	23.62 31.50 38.19			
Master C	mm	1200 800 970	228	0.9312	112.300
	in	47.24 31.50 38.19			
Master D	mm	600 800 1000	96	0.4800	53.100
	in	23.62 31.50 39.37			
Cont 20 FT*			6304		
Cont 40 FT*			12880		
HICUBE *			13008		