


Verbatim LED PAR16 GU10 7.3W 3000K Warm White 420 LM DIM


- GU10 Socket
- 220 - 240 V Voltage
- 35,000 hours Lifetime
- Dimmable
- 88% Energy Saving
- Equivalent to 60W incandescent bulb

Product Number	52235
General Data	
Lamp Socket	GU10
Electric Data	
Wattage (W)	7.3
Wattage Equivalent (W)	60
Voltage (V)	220 - 240 V
Dimmable	yes
Power Factor	0.9
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	56.6
Diameter (in mm)	49.9
Weight (g)	65
Photometric Data	
Luminous Flux 90° Cone (lm)	420
CRI	80
CCT (K)	3000
Luminous Intensity (cd)	800
Beam Angle (°)	36
Luminous Efficacy (lm/W)	58
Lifetime (hrs)	35,000
Switching Cycle	60,000

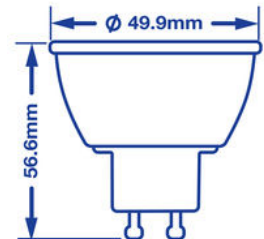

02/07/2014


Photometric Diagrams

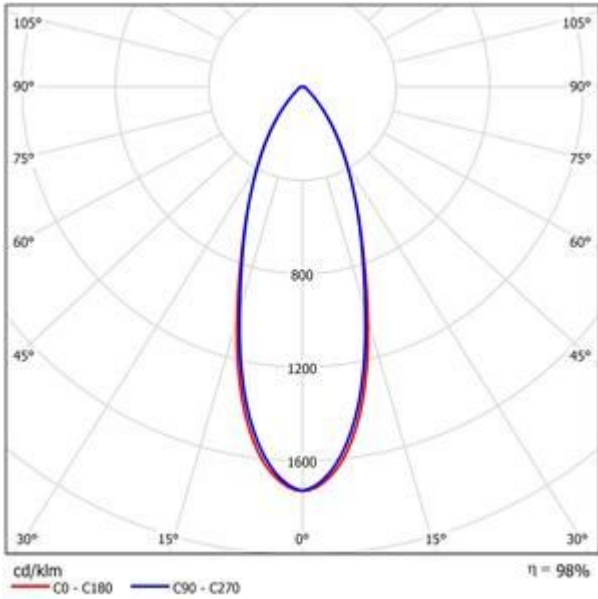

Distance [m]	Cone Diameter [m]	Illuminance [lx]
0.5	0.32	E(0°) 3232
	0.33	E(C90) 17.7° 1403
		E(C0) 18.2° 1390
1.0	0.64	E(0°) 808
	0.66	E(C90) 17.7° 351
		E(C0) 18.2° 348
1.5	0.96	E(0°) 359
	0.99	E(C90) 17.7° 156
		E(C0) 18.2° 154
2.0	1.28	E(0°) 202
	1.32	E(C90) 17.7° 88
		E(C0) 18.2° 87
2.5	1.60	E(0°) 129
	1.64	E(C90) 17.7° 56
		E(C0) 18.2° 56
3.0	1.91	E(0°) 90
	1.97	E(C90) 17.7° 39
		E(C0) 18.2° 39

Distance [m] Cone Diameter [m] Illuminance [lx]
 — C0 - C180 (Half-value Angle: 36.4°)
 — C90 - C270 (Half-value Angle: 35.4°)

Energy Rating

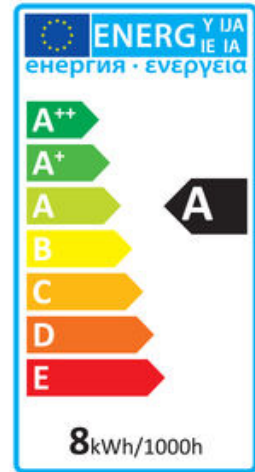

Technical Packaging Details

Barcode

023942522355

EAN 128

(02)00023942522355(37)10(91)162

EAN 14

50023942522350

Pack Dimensions (HxWxL)

H 65 x W 50 x L 50

Pack Weight

81

MOQ

10

Carton Dimensions (HxWxL)

H 58 x W 135 x L 287

Cartons/Pallet

256

Layers/Pallet

16

Units/Pallet

2560

02/07/2014