



SAMSUNG TECHWIN

Weather-resistant High Resolution Bullet Camera

960H Accessory Camera

SDC-7340BC

960H Weatherproof IR Camera

- 720TV lines of high resolution (SDC-7340BCN)
- True Day & Night with ICR for perfect color reproduction
- IP66 weather resistant rating
- Night vision up to 82ft



960H Weatherproof IR Camera SDC-7340BC




Kit Contents

- Camera [SDC-7340BC] 1pcs
- 60ft BNC Cable 1pcs
- Plastic Achors / Screws
- User Manual

	SDC-7340BCN		SDC-7340BCP
VIDEO			
Imaging Device	1/3" 960H CMOS		
Effective Pixels	976(H) x 494(V)		976(H) x 582(V)
Scanning System	Interlace		
Frequency	H : 15.734KHz / V : 59.94Hz		
Horizontal Resolution	720TV lines		700TV lines
Min. Illumination	Color : 7Lux B/W : 0Lux (IR LED on)		
S / N Ratio	46dB		
Min. Cable Length	60ft (18.3m) included		
LENS			
Focal Length	3.8mm		
Max. Aperture Ratio	F2.0		
Angular Field of View	H : 75° / V : 66° / D : 80°		
OPERATIONAL			
Shutter Mode	Auto (Rolling shutter)		
Gain Control	Auto		
White Balance	Auto (1,800°K ~ 10,500°K)		
Digital Noise Reduction	Auto		
Day & Night	Mechanical : Auto (ICR)		
IR Distance (850nm)	25m (82ft)		
ENVIRONMENTAL			
Operating Temperature / Humidity	-10°C ~ +50°C (+14°F ~+122°F) / 20% ~ 85%RH		
Storage Temperature / Humidity	-20°C ~ +60°C (+4°F ~+140°F) / 20% ~ 85%RH		
Ingress Protection	IP66 grade		
ELECTRICAL			
Input Voltage	12V DC		
Power Consumption	Max. 3W		
MECHANICAL			
Color / Material	White gray / Plastic (Poly carbonite)		
Dimensions (WxHxD)	72.1 x 62.9 x 192.4mm (2.84" x 2.48" x 7.57")		
Weight	252g (0.56 lb)		

Dimensions

Unit : mm (inch)

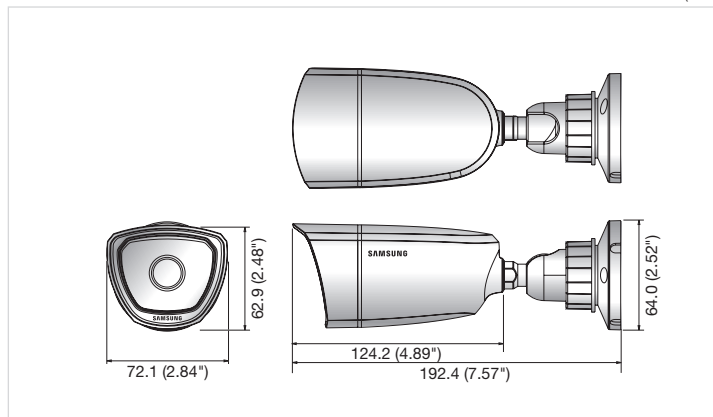

Design and specifications are subject to change without notice.



The Eco mark represents Samsung Techwin's will to create environment-friendly products, and indicates that the product satisfies the EU RoHS Directive.

SAMSUNG TECHWIN CO., LTD.

6, Pangyo-ro 319beon-gil, Bundang-gu, Seongnam-si, Gyeonggi-do, SEOUL 463-400 Rep. of KOREA
Tel : +82-70-7147-8741~8749, 8752~8760 Fax : +82-31-8018-3745 www.samsungsecurity.com www.samsungcctv.com
COPYRIGHT BY SAMSUNG TECHWIN. ALL RIGHT RESERVED

SAMSUNG TECHWIN AMERICA INC.
100 Challenger Rd. Suite 700 Ridgely Park, NJ 07660
Toll Free : +1-877-213-1222 Direct : +1-201-325-6920
Fax : +1-201-373-0124

SAMSUNG TECHWIN EUROPE LTD.
2nd Floor, No. 5 The Heights, Brooklands, Weybridge,
Surrey, KT13 0NY, UK
Tel : +44-1932-82-6700 Fax : +44-1932-82-6701

SHANGHAI SAMSUNG TECHWIN CO., LTD.
32F, Blk B, International Business Center,
No. 391 Guiping Rd., Shanghai, China, 200233
Tel : +86-21-5427-1155 Fax : +86-21-5423-5122



SAMSUNG TECHWIN