



A friend for life

# SAFELINE - A FULL RANGE OF PLIERS ENGINEERED FOR THE ELECTRICIAN

The Safeline pliers are made in Germany to meet all current relevant manufacturing standards set by ISO and DIN. They also meet the stringent safety standards of VDE 0680/201 and IEC 900 1987. This guarantees top quality and 100% Safety for the electrician.

Each plier is individually tested to 10,000 (AC 1000V) to ensure that the pliers are suitable for working around live parts of installations operating at 1000 V AC or 1500V DC.

## Features and Benefits:



HOT DROP FORGED STEEL  
- strength and durability

INDUCTION HARDENED CUTTING EDGES  
- long life, precision cutting



FINELY POLISHED AND CHROMIUM PLATED  
- rust protection and easy care

TEXTURED HANDLES AND HIGH SHOULDERS  
- non slip, less risk of bare metal contact

WELDED ANCHORS SECURE INJECTION MOLDED INSULATION  
- giving 100% non slip protection and guaranteed insulation thickness of at least 1mm, for dielectrical integrity.

CUTTING CAPACITY PRINTED ON HANDLE  
- less chance of misuse

All items marked thus: - ★★★ form part of VDE Electrical Tool Kit RS 181-323

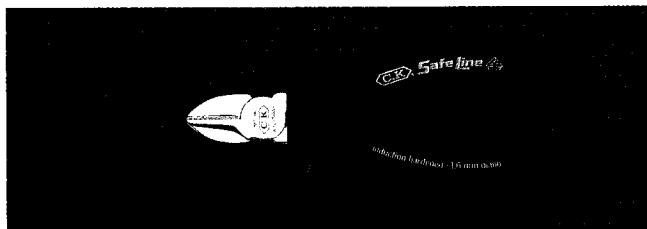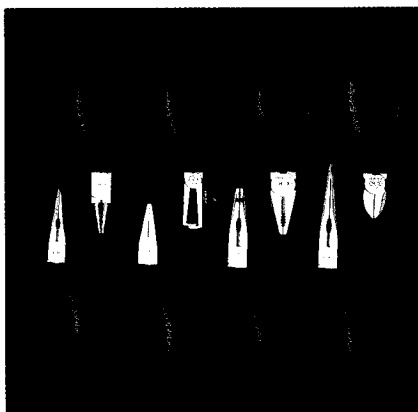


## Safeline SIDE CUTTERS 3666 ▲

Swedish pattern side cutters designed to cut piano wire with ease. Manufactured from hot drop forged special tool steel, oil hardened and tempered to specified levels. Induction hardened cutting edges to 60-61 HRC. Manufactured to VDE 0680/201, IEC 900 1987, ISO 5749, DIN 5238B and GS Specifications. Display packed.

Size:	145mm / 5 1/2"	160mm / 6"	180mm / 7"
Order Ref:	T3666 5	T3666 6	T3666 7
Weight:	215g	235g	300g
Box Qty:	3	3	3
Cutting Capacity mm Ø			
Piano Wire:	1.2	1.6	1.8
Hard Wire:	1.6	2.1	2.3
Med/Hard Wire:	2.5	2.9	3.0
Soft Wire:	> 4	> 4	> 4

VDE 0680/201, IEC 900 1987, ISO 5749, DIN 5238B, GS.

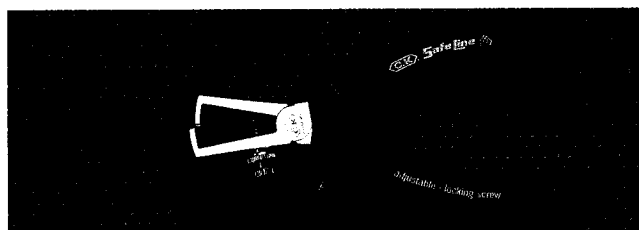

## Safeline WIRE STRIPPING PLIERS 3667 ▲

Excellent product for repetitive work with strong coiled spring and comfort handles. Adjustable stripping capacity of 0.3-5mm diameter wire utilising the brass setting screw and lock nut. Manufactured to VDE 0680/201, IEC 900 1987, DIN 5232 and GS Specifications. Display packed.

Size:	160mm / 6"
Order Ref:	T3667
Weight:	200g
Box Qty:	3

VDE 0680/201, IEC 900 1987, DIN 5232, GS.




AC1000V



### WARNING

Do not use on live circuits. For use around live circuits not exceeding 1000V AC. Do not touch non insulated areas of Safeline when in use. Do not use Safeline if insulation appears damaged in any way eg voids, cracks or breaks. Visually inspect Safeline before every use. Safeline must be kept clean and dry for continuing insulation properties and longer life.

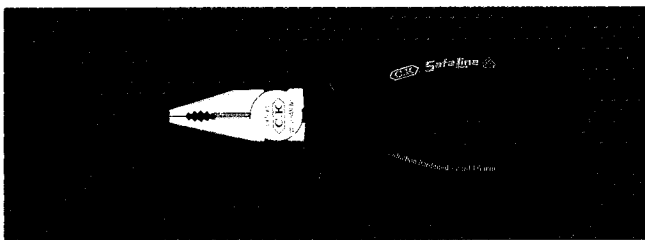


**Safeline COMBINATION PLIERS 3665 ▲**

Combination pliers featuring rod gripping hole and extra long cutting edges for round and flat cable. Has Safeline features which meet all current safety standards. Manufactured to VDE 0680/201, IEC 900 1987, ISO 5746, DIN 5244 and GS Specifications. Display packed. ★★★

Size:	160mm / 6"	180mm / 7"	200mm / 8"
Order Ref:	T3665 6	T3665 7	T3665 8
Weight:	245g	290g	360g
Box Qty:	3	3	3
Cutting Capacity: mm Ø			
Hard Wire:	1.6	1.6	2.0
Med/Hard Wire:	2.5	2.5	2.8
Soft Wire:	> 4.0	> 4.0	> 4.0

VDE 0680/201, IEC 900 1987, ISO 5746, DIN 5244, GS.

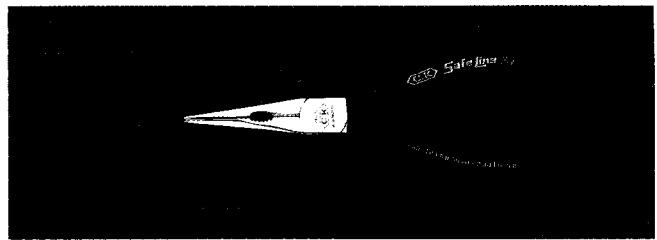


**Safeline SNIPE NOSE PLIERS 3668 ▲**

Manufactured from hot drop forged chrome vanadium steel, oil hardened and tempered with induction hardened cutting edges to 56-58 HRC. Rod gripping hole cutting edge and cut inside jaws. Manufactured to VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5236A and GS Specifications. Display packed. ★★★

Size:	165mm / 6 1/2"
Order Ref:	T3668
Weight:	186g
Box Qty:	3
Cutting Capacity: mm Ø	
Hard Wire:	1.6
Med/ Hard Wire:	2.5
Soft Wire:	> 4.0

VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5236A, GS.

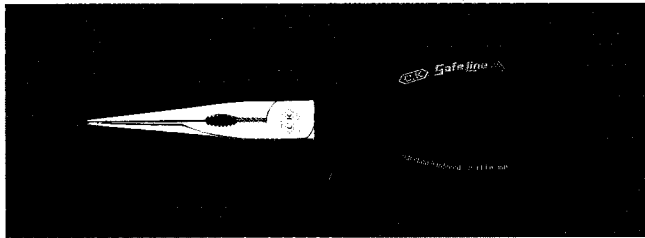


**Safeline SNIPE NOSE PLIERS 3669 ▲**

Specification as 3668 but longer overall length, with all Safeline features. Manufactured to VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5236A and GS Specifications. Display packed. ★★★

Size:	200mm / 8"
Order Ref:	T3669
Weight:	240g
Box Qty:	3
Cutting Capacity: mm Ø	
Hard Wire:	1.6
Med/ Hard Wire:	2.5
Soft Wire:	> 4.0

VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5236A, GS.

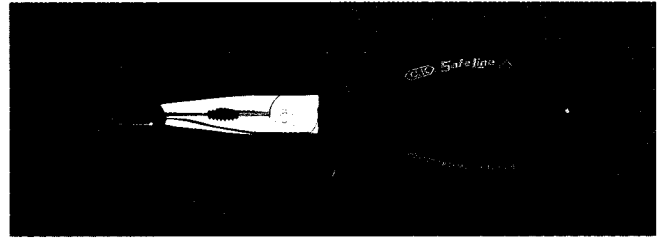


**Safeline SNIPE NOSE PLIERS 3663 ▲**

45° Bent snipe nose pliers with rod gripping hole, cutting edge and cut inside jaws with all Safeline Features. Manufactured to VDE 0680/201, IEC 900 1987, ISO 5745 DIN 5236B and GS specifications. Display packed. ★★★

Size:	200mm / 8"
Order Ref:	T3663
Weight:	230g
Box Qty:	3
Cutting Capacity: mm Ø	
Hard Wire:	1.6
Med/ Hard Wire:	2.5
Soft Wire:	> 4.0

VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5236B, GS.

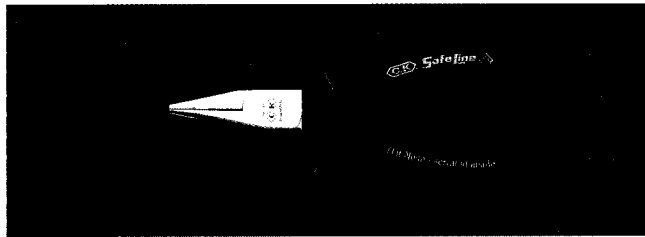


**Safeline FLAT NOSE PLIERS 3661 ▲**

Made from hot drop forged special tool steel, correctly hardened and tempered. Cut inside jaws for ease of use. With all Safeline safety and comfort features. Manufactured to VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5258 and GS Specifications. Display packed. ★★★

Size:	160mm / 6"
Order Ref:	T3661
Weight:	228g
Box Qty:	3

 VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5258, GS.



**Safeline ROUND NOSE PLIERS 3662 ▲**

Cut inside jaws for ease of use. Manufactured to meet all current safety standards including VDE 0680/201, IEC 900 1987 and ISO 5745, DIN 5257 and GS specifications Display packed. ★★★

Size:	160mm / 6"
Order Ref:	T3662
Weight:	205g
Box Qty:	3

VDE 0680/201, IEC 900 1987, ISO 5745, DIN 5257, GS.