


Audio Cables

FLAT SPEAKER CABLES: 4030 SERIE

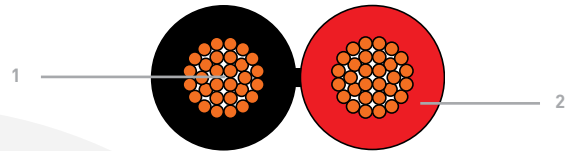

40304089

1. Composition of core: multi-strand bare copper
2. Jacket: PVC

APPLICATIONS

- Wiring of all types of sound systems
- Wiring of fixed and mobile installations
- 100 V installations

PRODUCT ADVANTAGES

- Good price/quality ratio
- Easy to install
- Identification of conductor by means of color code

SUITABLE PLUGS

- Cinch, Jacks, Din

ELECTRICAL CHARACTERISTICS


- Operating voltage: 900 V

MECHANICAL CHARACTERISTICS

- Operating temperature: Fixed station: - 25°C +70°C
Mobile station: - 5°C +70°C
- Bend radius: 8 x Outer diameter

Part Nb	Nb of conductors	Section	Jacket	Outer diameter	Packaging
4030.5082N	2	0.50 mm ²	Black PVC	1.80 x 3.70 mm	100 m
4030.5082B	2	0.50 mm ²	White PVC	1.80 x 3.70 mm	100 m
4030.4008	2	0.50 mm ²	Red / black PVC	1.80 x 3.70 mm	100 m
4030.5067N	2	0.75 mm ²	Black PVC	2.10 x 4.20 mm	100 m
4030.5067B	2	0.75 mm ²	White PVC	2.10 x 4.20 mm	100 m
4030.5067G	2	0.75 mm ²	Grey PVC	2.10 x 4.20 mm	100 m
4030.4089	2	0.75 mm ²	Red / black PVC	2.40 x 4.20 mm	100 m
4030.5122N	2	1.00 mm ²	Black PVC	2.40 x 4.80 mm	100 m
4030.5122G	2	1.00 mm ²	Grey PVC	2.40 x 4.80 mm	100 m
4030.5122B	2	1.00 mm ²	White PVC	2.40 x 4.80 mm	100 m
4030.4150	2	1.00 mm ²	Red / black PVC	2.40 x 4.80 mm	100 m
4030.5126N	2	1.50 mm ²	Black PVC	2.60 x 5.20 mm	100 m
4030.5126B	2	1.50 mm ²	White PVC	2.60 x 5.20 mm	100 m
4030.5126G	2	1.50 mm ²	Grey PVC	2.60 x 5.20 mm	100 m
4030.7126RN	2	1.50 mm ²	Red / black PVC	2.60 x 5.20 mm	100 m

FLAT SPEAKER CABLES: **FLAT TWIN SERIE**

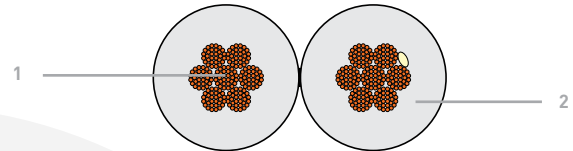

40306150

1. **Composition of core:** multi-strand bare oxygen-free copper
 4030.6150: 84 x 0.15 mm
 4030.6200: 112 x 0.15 mm
 4030.6250: 140 x 0.15 mm
 4030.6400: 255 x 0.15 mm

Coding of conductors: + conductor: striped
 - conductor: round

2. **Jacket:** Transparent PVC

APPLICATIONS

- Wiring of all types of sound systems
- Hi-Fi
- Wiring of fixed and mobile installations

PRODUCT ADVANTAGES

- Oxygen-free copper
- Double identification of conductors:
- High flexibility

SUITABLE PLUGS

- Cinch, Jacks, Din

ELECTRICAL CHARACTERISTICS

- Operating voltage: 100 V

MECHANICAL CHARACTERISTICS

- Operating temperature: Fixed station: - 30°C +70°C
 Mobile station: - 10°C +70°C
- Bend radius: 8 x Outer diameter

Part Nb	Nb of conductors	Section	Jacket	Outer diameter	Packaging
4030.6150	2	1.50 mm ²	PVC transparent	3.40 x 7.80 mm	100 m
4030.6200	2	2.00 mm ²	PVC transparent	3.50 x 8.00 mm	100 m
4030.6250	2	2.50 mm ²	PVC transparent	3.80 x 8.60 mm	100 m
4030.6400	2	4.00mm ²	PVC transparent	4.60 x 9.60 mm	100 m