


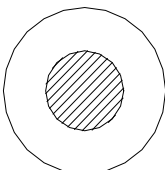

Datasheet

Product Name:	MIL-W-16878/5 26AWG
Product Discription:	MIL-W-16878/5 26AWG
Specification No.:	
Customer's Name:	

Description					Construction						
Rated Voltage:		1000V			Conductor		Stranded Sliver plated copper				
Rated Temperature:		200℃			Size(AWG)		26				
Reference Standard:		MIL-W-16878/5			Construction(±0.008mm)		19/0.10				
Cross Section					Stranded Dia.(mm)Ref.		0.5				
					Insulation Material		PTFE				
					Insulation Color		ANY COLOR				
					Ave Thickness(mm)		0.38				
					Insulation Dia.(±0.08mm)		1.26				
Marking					Remark:						
No marking on the cable jacket					8775465 Red		8775456 Blue				
					8775459 Black		8775468 White				
					8775452 Brown						
Applications					Characteristics				Customer Approve		
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					Test Item			Standard Value			Seal & Stamp
					Test Material			PTFE(ROHS)			
					Insulation resistance(20℃ MΩ*m			1000			
					Vol. Tesr(AC.V.60S) (V)			2000			
					Flammability Test			VW-1			
Revisions					Max.DC Resistance(20℃ Ω/km)			122.37(MAX)			
Version	Description	Drawn by	Approved by	Date							
0	New document issue	Danniel	Jason	19/05/2015							
				</							

Seal & Stamp

Signature:

Date: