


## Overvoltage Protection Acoustic 6+6-fold plus

Item No.: 0232x02062301

- Robust plastic body, grey
- 90° rotated sockets Type E (French Standard)
- Space of sockets: 64 mm
- 1,5 m power cord and angle plug
- Each socket is switchable with a bipolar illuminated switch
- Optical function and acoustic trigger signal
- The connected devices will remain in operation after release overvoltage protection
- Increased safety due to integrated child protection
- End caps with mounting facilities and spare fuse

### Technical Data

Voltage $U_n$ :	230 V~
Rated current (-Power):	16 A (3600 W)
Max. continuous operation voltage $U_c$ :	255 V~
$U_{oc}$ :	5000 V
Protection level $U_p$ :	L-N < 1,0kV - L/N-PE < 1,5kV
$I_{max}$ (8/20):	6,5 kA
Fuse:	T6,3AH/250 V
SPD according to EN 61643-11	Typ3
Power cord:	1,5 m H05VV-F 3G 1,5 mm <sup>2</sup>
Plug:	CEE 7/7 angle plug Type EF
Sockets:	Middle-earth Type E
Consumption per switch:	< 0,5 W
Consumption overvoltage protection:	< 0,1 W
Dimensions:	846 x 74 x 47 mm (L x B x H)
Fixing dimension:	838 mm
EAN:	401209600498 1
Packaging unit:	10 pc.

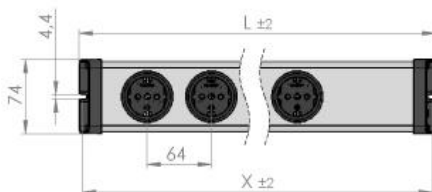

**VARIO®**  
**LINEA**