

## Front adapters - FLKM 50-PA-AB/1756/IN/EXTC - 2302748

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)




VARIOFACE front adapters, for Allen Bradley ControlLogix and Honeywell PlantScape, input card IB 32. The front adapters are pushed into the high 1756-TBE hoods (not supplied as standard).

The illustration shows the version  
FLKM 50-PA-AB/1756/IN/EXTC



### Key commercial data

Packing unit	1 pc
GTIN	 4 017918 910471
Weight per Piece (excluding packing)	62.7 g
Custom tariff number	85369010
Country of origin	Germany

### Technical data

#### General

Nominal voltage $U_N$	< 50 V AC
	60 V DC
Max. permissible current	1 A (per path)
Channels which can be connected	32
Connection type, connector	IDC/FLK pin strip (2.54 mm)
Number of connectors	1
No. of positions, connector	50
Number of positions	50
Mounting position	any
Standards/regulations	IEC 60664
	DIN EN 50178
	IEC 62103
Pollution degree	2
Surge voltage category	II

#### Ambient conditions

# Front adapters - FLKM 50-PA-AB/1756/IN/EXTC - 2302748

## Technical data

### Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

### Connection data, power supply

Connection method	Pluggable screw connection
Conductor cross section stranded min.	0.14 mm <sup>2</sup>
Conductor cross section stranded max.	1.5 mm <sup>2</sup>
Conductor cross section solid min.	0.14 mm <sup>2</sup>
Conductor cross section solid max.	1.5 mm <sup>2</sup>
Conductor cross section AWG/kcmil min.	28
Conductor cross section AWG/kcmil max	16

### Supported controller

Control	ALLEN-BRADLEY ControlLogix
- suitable I/O card	1756-IB32
Control	HONEYWELL PlantScape
- suitable I/O card	TC-IDD 321

## Classifications

### eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242208
eCl@ss 7.0	27242208
eCl@ss 8.0	27242208

### ETIM

ETIM 2.0	EC001423
ETIM 3.0	EC001423
ETIM 4.0	EC001423
ETIM 5.0	EC002584

### UNSPSC

UNSPSC 6.01	30211824
UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421

# Front adapters - FLKM 50-PA-AB/1756/IN/EXTC - 2302748

## Approvals

Approvals

---

Approvals

UL Recognized / cUL Recognized / cULus Recognized

---

Ex Approvals

---

Approvals submitted

---

## Approval details


UL Recognized

cUL Recognized

cULus Recognized

## Drawings

Circuit diagram

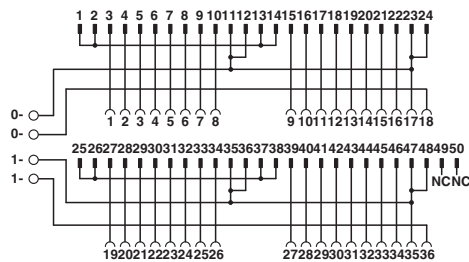

Connection scheme: FLKM 50-PA-AB/1756/IN/EXTC