

ENCLOSURE FOR 22MM PROGRAM PLASTIC VERSION 2
COMMAND POSITIONS GRAY TOP PART











Enclosure:	
Design of the housing	Empty enclosure for command and signaling devices
Shape of the enclosure front	rectangular
Material of the enclosure	plastic
Number of command points	2
Product component	
• protective collar	No
Color	
• of top part of the enclosure	grey
Delivery state	
• as a kit	No
• pre-wired on strip terminal	No
Mounting type of the enclosure	Vertical / horizontal

Actuator:	
Product feature	
• lockout	No
Product expansion optional Light source	Yes

Front ring:	
-------------	--

Product component front ring	No
General technical data:	
Product function	
• positive opening	No
• EMERGENCY STOP function	No
Product component	
• Light source	No
• Stand/pedestal	No
Vibration resistance	
• acc. to IEC 60068-2-6	20 ... 200 Hz: 5g
Protection class IP	IP65
Equipment marking	
• acc. to DIN 40719 extended according to IEC 204-2 acc. to IEC 750	S
• acc. to DIN EN 61346-2	U
• acc. to DIN EN 81346-2	U
Connections/ Terminals:	
Type of electrical connection on enclosure	Cable routing above, below / left, right, each 1 x M20
Ambient conditions:	
Ambient temperature	
• during operation	-25 ... +70 °C
• during storage	-40 ... +80 °C
Environmental category during operation acc. to IEC 60721	3K6
Installation/ mounting/ dimensions:	
Mounting type	
• of contact blocks, socket, and accessories	Floor mounting / front mounting (1-pole)
Height	114 mm
Width	85 mm
Depth	64 mm
Shape of the installation opening	round
Mounting diameter	22 mm
Accessories:	
Number of labels	2
Product component holder for 3 switching elements	No
Certificates/ approvals:	

General Product Approval		Declaration of Conformity	Test Certificates	Shipping Approval
 CSA	 UL		 EG-Konf.	spezielle Prüfbescheinigung <u>n</u>
				 ABS

Shipping Approval	other
 DNV	Bestätigungen
 LRS	Umweltbestätigung
 PRS	

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrymall>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3SB38020AA3>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3SB38020AA3>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SB38020AA3&lang=en

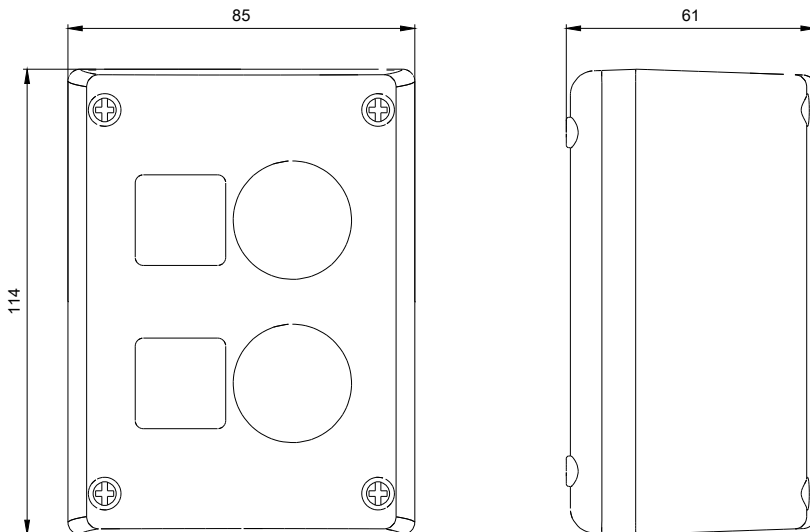

W9.4444; 3SB3802-0AA3

last modified:

28.07.2015