

## Docking frames - HC-B 16-ANDOCK-MOD-T - 1587454

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Docking frame for four module slots, floating assembly, plastic without PE, rack compensation of +/-2.0 mm in the x/y-axis, for M4 cylinder head screws

### Product description

Docking frame, fitted floating. Made from plastic without PE. Slide-in offset x/y axis +/- 2.0mm



### Key commercial data

Packing unit	2 pc
Minimum order quantity	2 pc
GTIN	 4 046356 526432
Weight per Piece (excluding packing)	24.1 g
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### General

Material	PC
Inflammability class according to UL 94	V0
Type	B16

### Classifications

#### eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27261209
eCl@ss 7.0	27440206

# Docking frames - HC-B 16-ANDOCK-MOD-T - 1587454

## Classifications

### ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC002312
ETIM 4.0	EC000437
ETIM 5.0	EC002310

### UNSPSC

UNSPSC 6.01	43172601
UNSPSC 7.0901	39121416
UNSPSC 11	43172601
UNSPSC 12.01	39121408
UNSPSC 13.2	39121408

## Approvals

### Approvals

---

#### Approvals

EAC

---

#### Ex Approvals

---

#### Approvals submitted

---

### Approval details

EAC
-----

## Accessories

### Accessories

#### Mounting material

Washer - HC-MOD-ANDOCK-USCH - 1587496




Special washer for floating mounting of docking frame

# Docking frames - HC-B 16-ANDOCK-MOD-T - 1587454


## Drawings

Dimensioned drawing

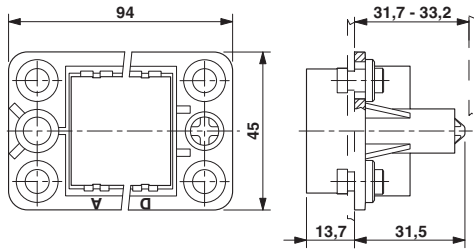

Dimensional drawing of HC-B 16-ANDOCK-MOD...

Dimensioned drawing

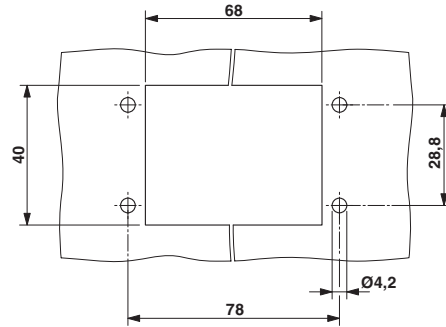

Mounting cutout for HC-B 16-ANDOCK-MOD...