


ZEN4 LED DOWN LIGHT KIT 11W ~ 4" 82lm/W



- Bright lumen output, low glare
- High efficiency LED chip and reflector system
- Quick connect external dimmable driver included compatible with leading edge & trailing edge dimmer
- Energy savings of 85% & low maintenance costs
- Anodised aluminium heat sink
- Long life - 50k hours
- 90° beam angle
- Insulation spacer frame ~ Low heat generation

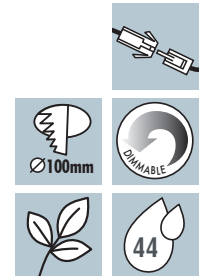


ZEN ~ 4" Specification

Model Number	ZEN4 11W3K-W	ZEN4 11W4K-W	ZEN4 11W3K-SN	ZEN4 11W4K-SN
Fitting Colour	White	White	Satin Nickel	Satin Nickel
Input Current	350mA			
Input Voltage	31V			
Power	11W			
Lumens	850lm	900lm	850lm	900lm
Colour (K)	3000	4000	3000	4000
Lumen Field Angle	90°			
Working Temperature	-20°C ~ +40°C			
CRI	80			
Weight	300g			
Dimensions	Ø120 x 103mm			

Optional
Emergency
pack available
~ EP3


Mechanical Diagram

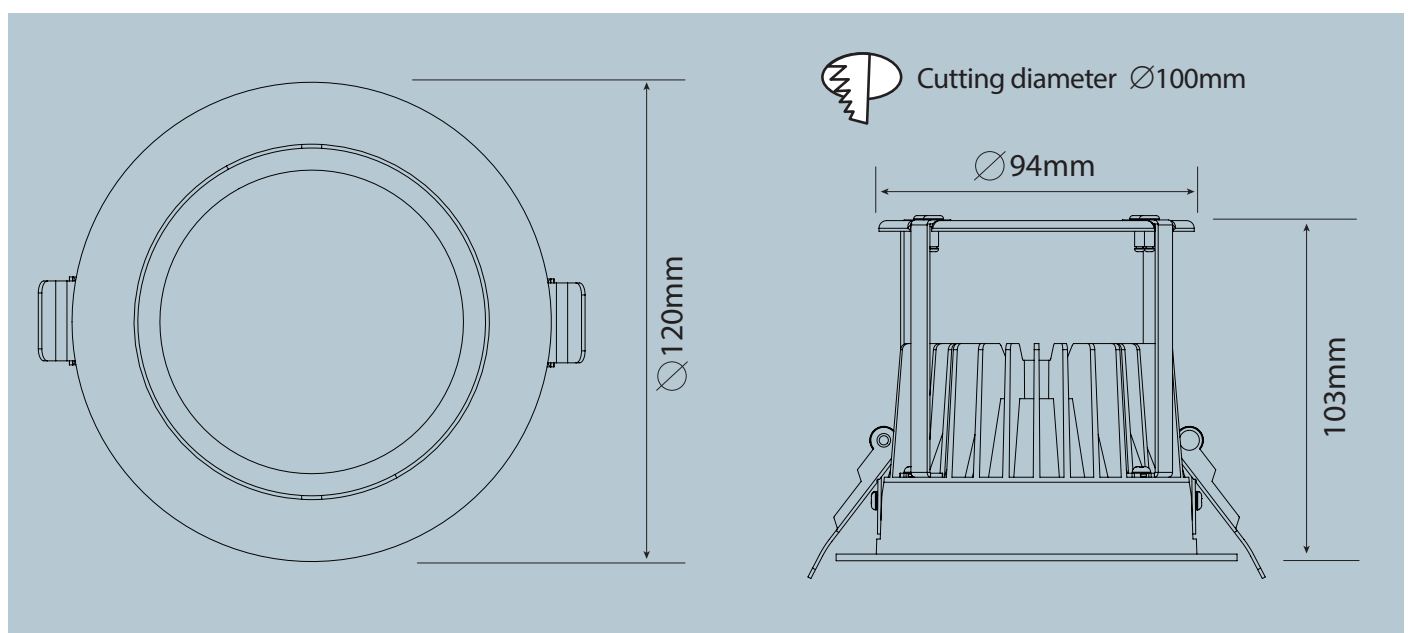


ZEN4 LED DOWN LIGHT KIT 11W ~ 4" 82lm/W



Photometrics

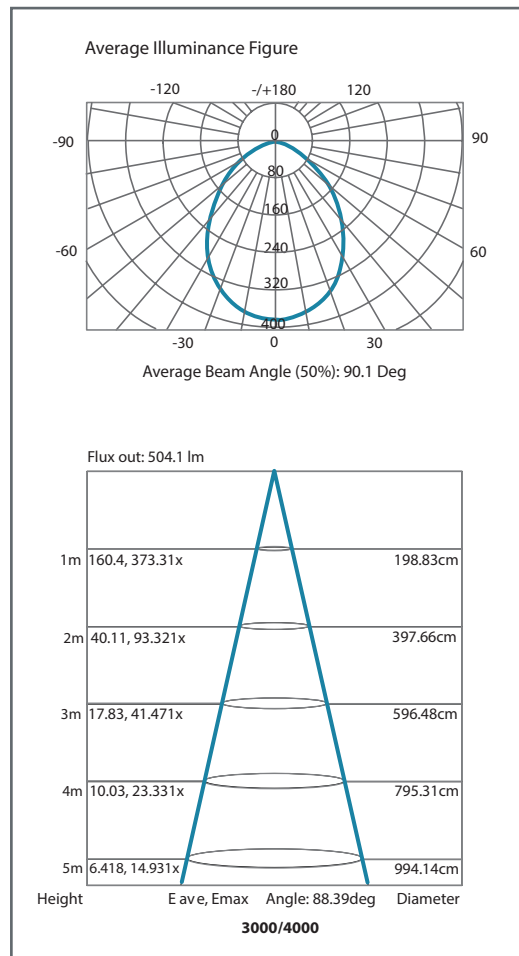

Installation

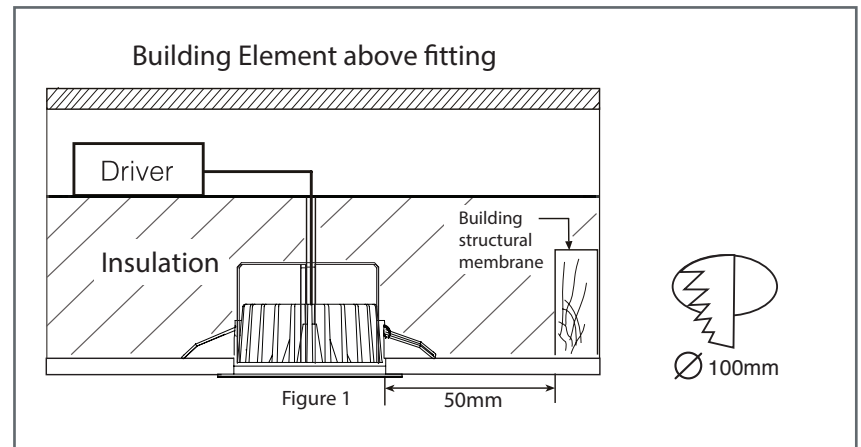

Driver Connection

