

# ET 239



Euromas II  
Enclosure, ABS

Order no.: 63239000

**Colour of enclosure group**

Light grey, similar to RAL 7035; special colours on request


**Protection class**

IP 65/DIN EN 60529; higher ingress protection on request

**Enclosure material**

ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information

Scope of delivery: Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

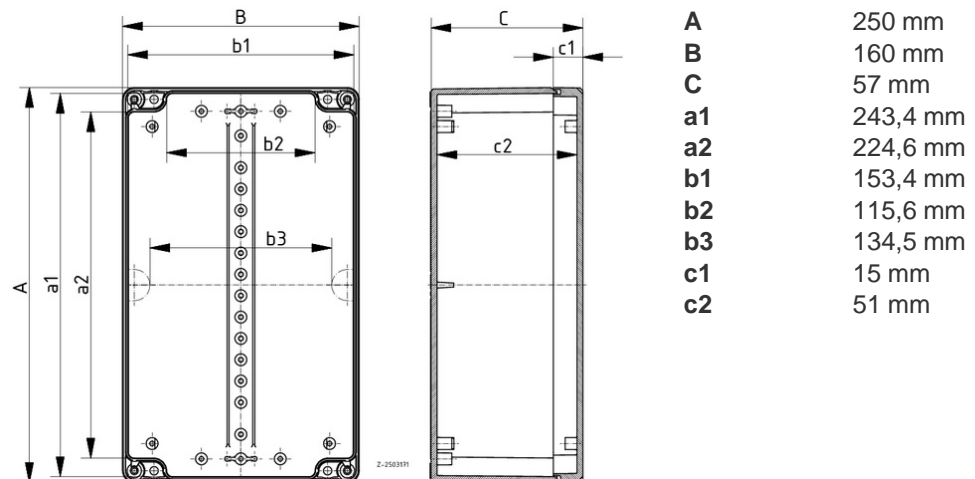

**Technical drawings**

Catalogue drawing in DXF format:

[63239000\\_ET-239.dxf](#) (1.2 MB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[63239000\\_ET-239-G.dxf](#) (636 KB)

Catalogue drawing in PDF format:

[63239000\\_ET-239.pdf](#) (129 KB)

**Chapter download**

[Euromas II\\_GB.pdf](#) (362 KB)

## Accessories



### Rubber feet, self-adhesive

22009000 [GF](#)

Polyurethane, 65-75 Shore Black



### Wall brackets, screw-on at rear

22010000 [EM-WL](#)



### Screw covers

22080000 [EM-SA](#)



### Mounting panels, laminated paper

22000900 [M](#)

For EM/ET 239-241, M/T 240, M/T 241, M/T 250



### DIN rail acc. to DIN EN 60715 TH 15

22152301 [TS 15](#)

For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)



### DIN rail acc. to DIN EN 60715 G 32

22322301 [TS 32](#)

For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise)



### DIN rail acc. to DIN EN 60715 TH 35

22352301 [TS 35](#)

For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B



2617.., B 2736.. (crosswise)

\* = Available on request