


# 12 40 200

## Self-Adjusting Insulation Stripper



- for single, multiple and fine stranded conductors with plastic or rubber insulation
  - adapts automatically to the respective cable cross-section; prevents damage to the conductor
  - cutting depth can be adjusted for different insulation materials
  - with wire cutter for copper and aluminium wires, multiple stranded up to 10 mm<sup>2</sup> and single stranded up to 6 mm<sup>2</sup>
  - smoothly operating mechanism
  - stripping blades and clamping jaws easily replaceable
  - low weight
  - body: plastic, fibreglass-reinforced
  - blade: special tool steel, oil-hardened
- MM
- for thin ribbon cables up to 10.0 mm width in a single pass

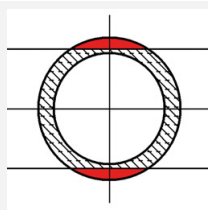

### Mode of operation of straight cutters

Models 12 40 200 and 12 42 195

An incision is made in the red area only.

Not suitable for highly-flexible or armoured insulation materials or for multi-layered insulation.


<b>Article No.</b>	12 40 200
<b>EAN</b>	4003773026662
<b>Stripping capacities mm<sup>2</sup></b>	0,03 - 10,0
<b>Length stop mm</b>	3,0 - 18,0
<b>Nominal size</b>	200 mm
<b>AWG</b>	32 - 7
<b>Length mm</b>	200
<b>Net weight g</b>	202



12 40 200: Adjustable length stop



Wire cutter for multiple stranded wire cables up to 10.0 mm<sup>2</sup>

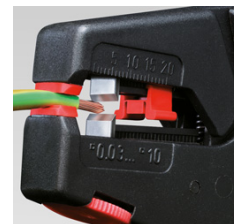

12 40 200: Precise stripping prevents damage to the conductor

technical change and errors excepted



### Spare Parts

Article No.	EAN	
12 49 01	4003773026679	1 pair of spare blades for 12 40 200
12 49 02	4003773026686	1 pair of spare clamping jaws for 12 40 200
12 49 03	4003773026693	Spare length stop for 12 40 200
12 49 04	4003773053071	Torsion spring for 12 40/50 200
12 49 05	4003773053088	Pressure spring in the head for 12 40/50 200