


# Datasheet

## Stainless Steel Toggle Latch, Lockable 30kgf Op. Tension

RS Stock number [206-4652](#)

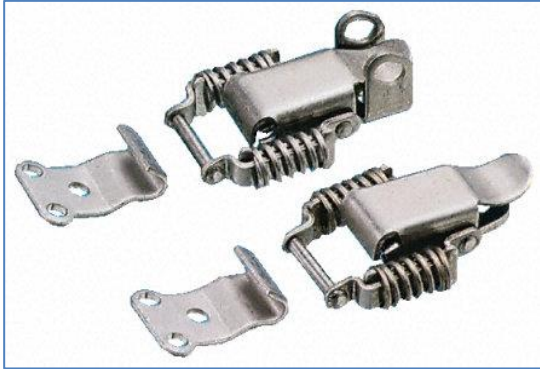

### Description:

Similar in design to the variable tolerance versions but smaller.

Wide positioning tolerance created by the spring mechanism

Failsafe design prevents over extension of links

Operating tension is 20 kgf when distance between Catch fixing hole centres and the furthest Latch fixing hole centre is 63.2 mm

Maximum operating tension is 30Kgf.

Use 4 x M4 screws for fixing

### Features:

- Dimensions 53 x 35 x 17mm
- Lockable Yes, Lock Not Included
- Material Stainless Steel
- Operating Tension 30kgf
- Spring Loaded Yes

