




Datasheet

Stock No: 712-5294


ENGLISH

RS Pro Blue Equipment Wire, 0.28mm² CSA, 1000 V 1.8 A 23 AWG, 100m

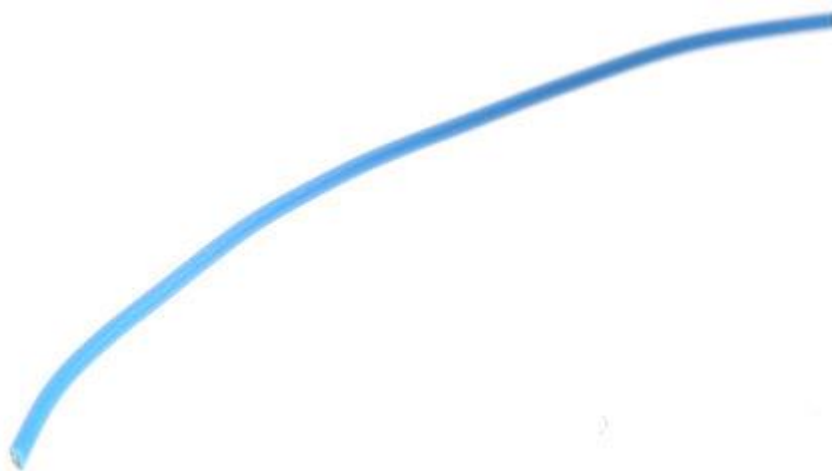

Cable Construction

Conductor	Tinned Copper
square(mm ²)	0.28
Construction	T0.60±0.01
Standard Dia.(mm)	0.60
Insulation	PVC
Thickness	0.3
Insulation Dia.(±0.1mm)	1.20

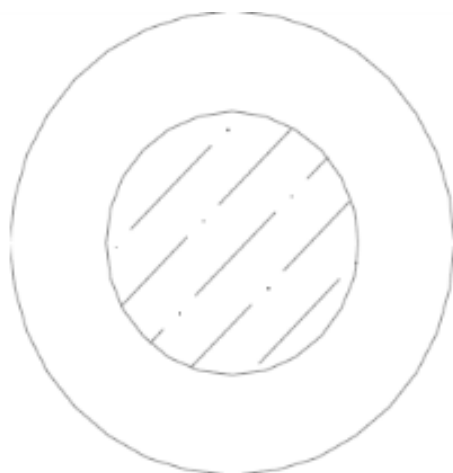

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<67
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	70
Rated Voltage (V)	1000