


# STANLEY

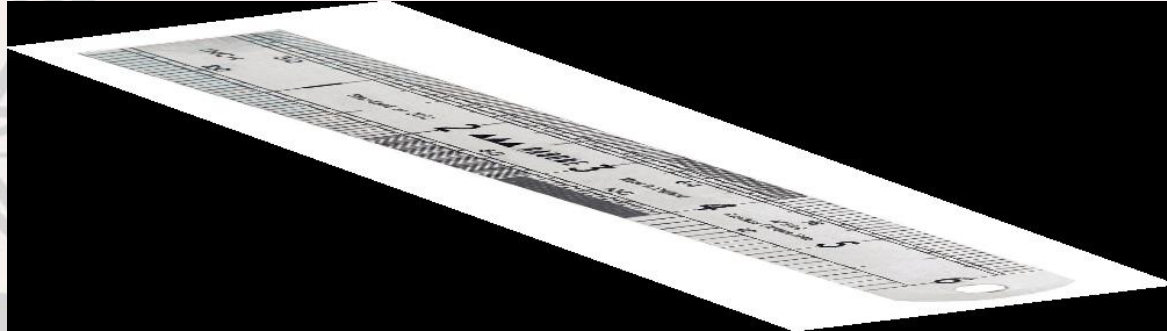

## **Stanley 0-35-400**

150mm/6"19mm wide

0.45mm thickness

Engineers' precision steel rules

- Imperial side graduated to 16ths, 32nds, 64ths, 10ths, 20ths, 50ths, 100th
- Metric side graduated to 0.5mm
- Class I accuracy