





TRIP ALARM SWITCH CHANGEOVER CONTACTS
TYPE HQ (7MM) ACCESSORY FOR 3VA-BREAKER



Model		
product brand name		SENTRON
General technical data		
Thermal current	A	6
Overtoltage category		III
Voltage		
Insulation voltage / Rated value	V	690
Surge voltage resistance / Rated value	kV	4
Operating voltage		
• at AC / at 50 Hz / Rated value / minimum	V	240
• at DC / Rated value / minimum	V	250
Wire stripping length	mm	15
Connectable conductor cross-section / maximum	mm ²	1.5
Tightening torque / with screw-type terminals / maximum	N·m	0.5
Height	mm	56
Width		
• Note		1 slot (7 mm)

Depth	mm	30
Net weight	g	30
Degree of pollution		3

General Product Approval	EMC	Declaration of Conformity	Test Certificates
 CCC	 VDE		 EG-Konf.

[sonstig](#)

[Typprüfbescheinigung/Werkszeugnis](#)

other
sonstig

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3VA99880AB12>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3VA99880AB12/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA99880AB12

CAX-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

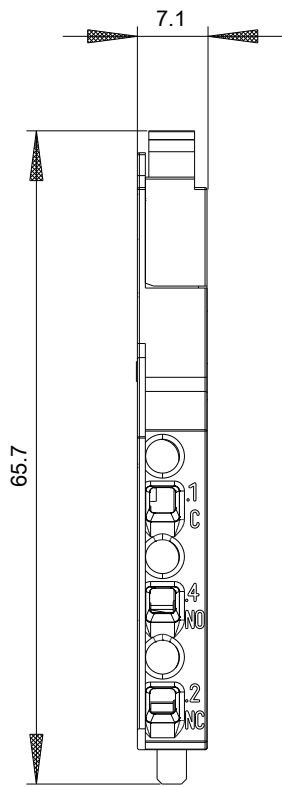

last modified:

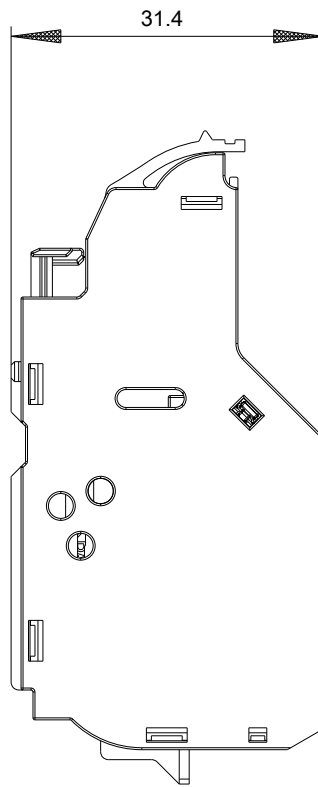

20.07.2015