


AxiMax 400 Comm C0G, Ceramic, 100 pF, 5%, 100 VDC, C0G, AxiMax, Commercial Standard

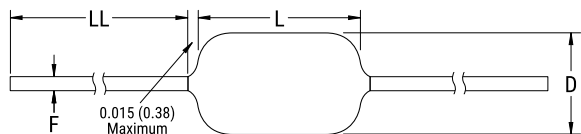

**Dimensions**

<b>D</b>	2.41mm MAX
<b>L</b>	4.32mm MAX
<b>LL</b>	25.4mm MIN
<b>F</b>	0.51mm +0.025/-0.076mm

**Packaging Specifications**

<b>Packaging:</b>	Bulk, Bag
<b>Packaging Quantity:</b>	300

**General Information**

<b>Supplier:</b>	KEMET
<b>Series:</b>	AxiMax 400 Comm C0G
<b>Description:</b>	AxiMax, Commercial Standard
<b>RoHS:</b>	Yes
<b>Termination:</b>	Tin
<b>Failure Rate:</b>	N/A
<b>Halogen Free:</b>	Yes

**Specifications**

<b>Capacitance:</b>	100 pF
<b>Capacitance Tolerance:</b>	5%
<b>Voltage DC:</b>	100 VDC
<b>Dielectric Withstanding Voltage:</b>	250 VDC
<b>Temperature Range:</b>	-55/+125C
<b>Temperature Coefficient:</b>	C0G
<b>Dissipation Factor:</b>	0.1% 25C
<b>Aging Rate:</b>	0% Loss/Decade Hour
<b>Insulation Resistance:</b>	100 GOhms