


EPIC® M23 A3

Sonderversion IP65
Neue Artikelnummern

Info
!!! Special Degree of Protection IP65 !!!

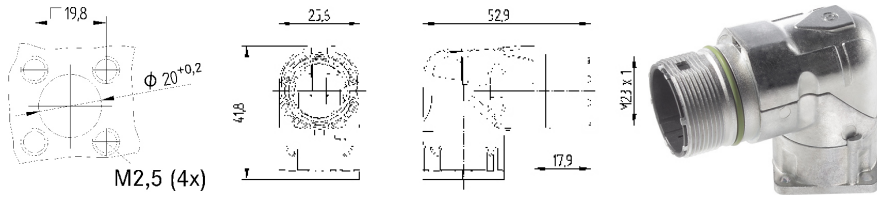

Benefits

- Housings are very flexible - cable connectors with huge clamping range, receptacle housings for insert assembly from front- and rear direction

Application range

- Plant engineering
- Servo drives and Servo harnessings
- Measurement and control technology

Product features

- Panel mount base, angled, rotatable

- Front mounting

Suitable inserts

- EPIC® M23 Inserts 6 pole]
- EPIC® M23 Inserts 7 pole
- EPIC® M23 Inserts 8+1 pole
- EPIC® M23 Inserts 9 pole
- EPIC® M23 Inserts 12 pole
- EPIC® M23 Inserts 16 pole
- EPIC® M23 Inserts 17 pole
- EPIC® M23 Inserts 12 pole D-Sub
- EPIC® M23 Inserts 17 pole D-Sub

Technical data

- Material**
Housing: zinc die casting nickel-plated
Sealing: FPM
- IP**
Degree of protection
IP65
- Range of temperature**
-25 °C - +125 °C

Part number	Part	Coding	Fastening type	Pieces / PU
Type M23 A3 angled rotatable front wall mounting				
24420055	M23 A3	black (N)	Ø2,7mm (4x)	5
24420054	M23 A3	black (N)	Ø2,7mm (4x)	20

Sonderversion IP65
Neue Artikelnummern